


COAXIAL CONNECTOR, QLA-01, 50 Ohm, Right angle PCB jack (female)

85_QLA-01-0-2/110_N

Properties

- The coupling mechanism provides a fast and reliable connection
- Intermateable with Lemo series 00.250
- Applicable in frequencies up to 1.4 GHz

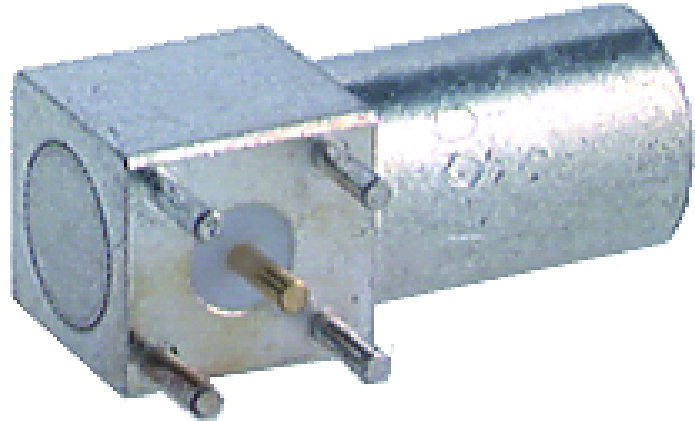

Product configuration

Interface type	Gender	Standard
QLA-01	jack	NIM-CAMAC-Standard CD/N549

Interface and material data

Piece parts	Material	Plating
Centre contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Outer conductor	Bronze	Gold Plating (Nickel underplated)
Body	Brass	Silver Plating
Insulator	PFA / PTFE	

Electrical data

Impedance	50 Ω
Interface frequency	1.4 GHz

Mechanical data

Weight	0.0043 kg
Mating cycles	10000
Board mounting type	through holes
Number of printlegs	4
Height above PCB HA	7 mm

Environmental data

Operation temperature	-55 °C ... 150°C
-----------------------	------------------

COAXIAL CONNECTOR, QLA-01, 50 Ohm, Right angle PCB jack (female)

85_QLA-01-0-2/110_N

Ordering Information Table		
Item number	Item description	Packaging type
22646483	85_QLA-01-0-2/110_NH	Bulk 100 pcs

Additional Information	
Remarks	PCB connector without stand-offs

HUBER+SUHNER is certified by ISO 9001, ISO 14001, ISO 45001, IATF 16949, AS/EN 9100 and ISO/TS 22163-IRIS. Waiver: Facts and figures herein are for information only and do not represent any warranty of any kind.
DOCUMENT PIM-P1279 / Date of publication: 26.11.2023 / uncontrolled copy