


COAXIAL CONNECTOR, PC 3.5, 50 Ohm, Straight panel receptacle, jack (female), flange mount

23_PC35-50-0-53/199_U

Properties

- Particularly well suited for semi-rigid, semi-flex and flexible cable
- Mechanical intermateable with SMA and PC 3.5 (3.5 mm standard)

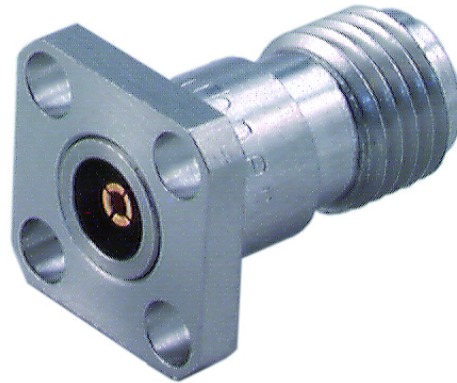

Product configuration

Interface type	Gender	Standard
PC 3.5	jack	IEC 60169-23

Interface and material data

Piece parts	Material	Plating
Centre contact	Copper Beryllium Alloy	Gold Plating (without Nickel underplating)
Outer conductor	Stainless steel	
Body	Stainless steel	
Insulator	PS (Polystyrene)	

Electrical data

Impedance	50 Ω
Interface frequency	26.5 GHz

Mechanical data

Weight	0.0035 kg
Mating cycles	500
Flange type	square flange / 12.7 X 12.7
Tab style	Socket

Environmental data

Operation temperature	-60 °C ... 100 °C
-----------------------	-------------------

COAXIAL CONNECTOR, PC 3.5, 50 Ohm, Straight panel receptacle, jack (female), flange mount
23_PC35-50-0-53/199_U

Material compliance			
Item number	Directive / Regulation	Rating	Exemptions / Details
22644910	RoHS 2011/65/EU and (EU) 2015/863	Compliant with exemption	6c
	REACH 1907/2006 Article 33 SVHC	Contains one or more SVHC >0,1%	CAS: 7439-92-1 Lead
Ordering Information Table			
Item number	Item description		Packaging type
22644910	23_PC35-50-0-53/199_UE		Single

HUBER+SUHNER is certified by ISO 9001, ISO 14001, ISO 45001, IATF 16949, AS/ EN 9100 and ISO/TS 22163-IRIS. Waiver: Facts and figures herein are for information only and do not represent any warranty of any kind.
DOCUMENT PIM-P2725 / Date of publication: 12.07.2025 / uncontrolled copy