


# COAXIAL CONNECTOR, TNC, X Ohm, Straight panel receptacle, jack (female), flange mount

23\_TNC-0-0-1

## Properties

- Threaded coupling mechanism improves control over the interface dimensions
- Used under a higher environmental load than BNC
- Available for 50 ohm and 75 ohm applications
- Applicable in frequencies up to 11 GHz

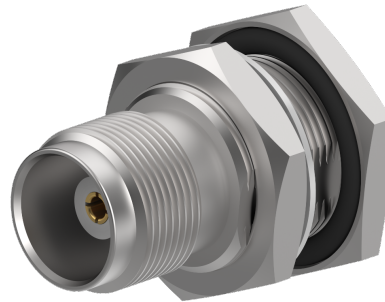

## Product configuration

|                |        |            |
|----------------|--------|------------|
| Interface type | Gender | Standard   |
| TNC            | jack   | ABS0708.01 |

## Interface and material data

|             |          |                |
|-------------|----------|----------------|
| Piece parts | Material | Plating        |
| Body        | Brass    | Nickel Plating |

## Mechanical data

|             |                        |
|-------------|------------------------|
| Weight      | 0.0079 kg              |
| Flange type | square flange / others |

## Material compliance

| Item number | Directive / Regulation            | Rating                          | Exemptions / Details |
|-------------|-----------------------------------|---------------------------------|----------------------|
| 22645848    | RoHS 2011/65/EU and (EU) 2015/863 | Compliant with exemption        | 6c                   |
|             | REACH 1907/2006 Article 33 SVHC   | Contains one or more SVHC >0,1% | CAS: 7439-92-1 Lead  |

## Ordering Information Table

| Item number | Item description |
|-------------|------------------|
| 22645848    | 23_TNC-0-0-1     |

HUBER+SUHNER is certified by ISO 9001, ISO 14001, ISO 45001, IATF 16949, AS/EN 9100 and ISO/TS 22163-IRIS. Waiver: Facts and figures herein are for information only and do not represent any warranty of any kind.  
DOCUMENT PIM-P2690 / Date of publication: 12.07.2025 / uncontrolled copy