

DOODLE LABS 2.4 GHZ OMNI ANTENNA

ANT-2450-3-O



ELECTRICAL DATA

Frequency Range 2400-2482 MHz

Peak Gain 3 dBi

VSWR < 1.5:1

Horizontal Beamwidth 360 Degrees

GENERAL DATA

Colour Black

Pigtail RG402

Connector Type SMA Male

Polarization Multi-polarized

Power 50 Watts Input

Impedance 50 ohms nominal

Construction ABS/6061 ALU

DOODLE LABS 2.4 GHZ OMNI ANTENNA

ANT-2450-3-O



MECHANICAL DATA

Length	137 mm
Diameter	25.4 mm
Mounting Type	Connector
Weight	22 g



ENVIRONMENTAL DATA

Environmental Condition	Indoor/Outdoor
Operation Temperature	-40°C to +85 °C
Storage temperature	-40°C to +85 °C
Transport temperature	-40°C to +85 °C
IP Rating	IP67

DOODLE LABS 2.4 GHZ OMNI ANTENNA

ANT-2450-3-O

Peak Gain: 3 dBi

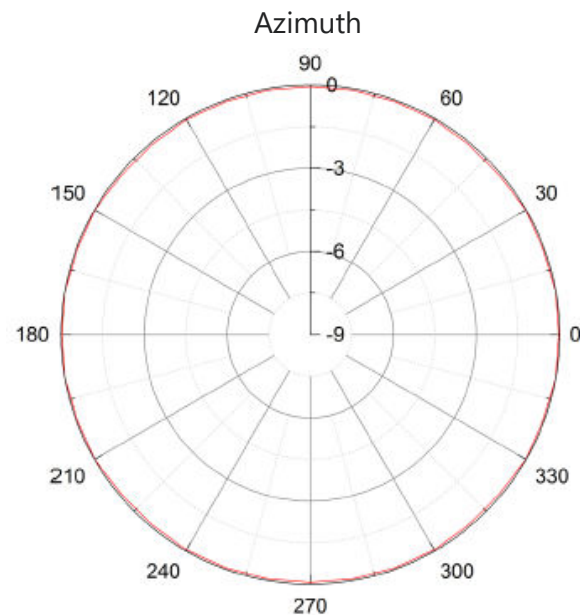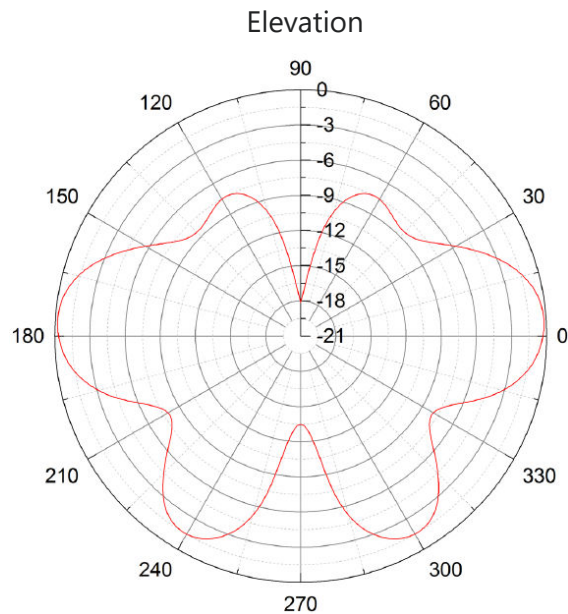

DOODLE LABS 2.4 GHZ OMNI ANTENNA

ANT-2450-3-O

Dimension are in mm

