



D-SUBMINIATURE CONNECTORS:

K61X Series

High Density Right Angle PCB Mount Compact Footprint

Product Features


15 Pin High Density D-Subminiature Receptacle, Right Angle PCB Termination, Compact Footprint
Available in Reflow Compatible, High Temperature Plastic

VESA Features

Contact #9 Recessed 0.050" (1.27mm) to Allow Last Mate/First Break on 5V Supply Voltage
Blue PBT Insulator Signifies 5V Capability and Full Feature AccessBus Capability in Accordance with Video Electronics Standard Association (VESA)
Meets Display Data Channel (DDC) Standard

K61X Series Dimensions

Dimensions in mm

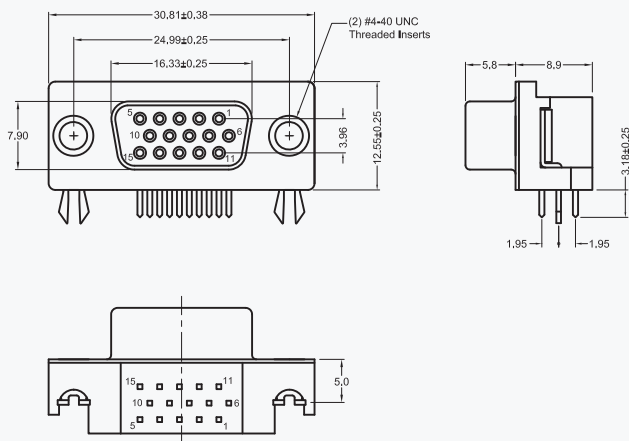

2D Drawing	IGES	STEP	3D PDF
Solder Profile	CofC RoHS Compliant	CofC REACH Compliant	UL Plastic File
Certificate of Origin	Check Stock	Request a Sample	Send Us An Email

Generated Part Number

Part Number Builder

	-					
Series		Shell Size Contact	Contact Type	Mounting Option	Plating Option	VESA Option

Series

K61X - High Density D-Subminiature Connector, Right Angle PCB Termination

Contact Shell Option

E - 15 Contacts

Contact Type

S - Socket Contact (Receptacle)

Mounting Option

N - With Boardlocks and #4-40 UNC Threaded Inserts
NJ - With Boardlocks and #4-40 Jackscrews Installed

Plating Option

Blank - Gold Flash
30 - 30μ" Gold

VESA Option

Blank - Standard
VESA - VESA Compliant Version

Contact Kycon for Other Options