


D-SUBMINIATURE CONNECTORS:

KF66X Series

Right Angle PCB Mount With Ferrite

KF66X Series Dimensions

Dimensions in mm

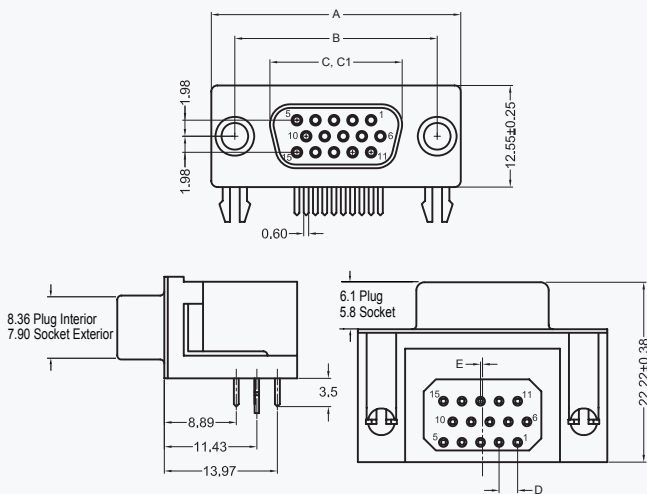

Shell Size	A	B	C	C1	D	E
In	± .015	± .005	± .010	± .010	± .005	± .005
mm	± 0.38	± 0.13	± 0.25	± 0.25	± 0.13	± 0.13
15	1.213	.984	.643	.666	.090	.010
(E)	30.81	24.99	16.33	16.92	2.29	0.25

C = Exterior of Female Shell (S)

C1 = Interior of Male Shell (P)

Electrical Characteristics

Rated Current: 1.5A

Rated Voltage: 29Vac

2D Drawing

IGES

STEP

3D PDF

Solder Profile

CofC RoHS Compliant

CofC REACH Compliant

UL Plastic File

Certificate of Origin

Check Stock

Request a Sample

Send Us An Email

Generated Part Number

Part Number Builder

	-				
Series		Shell Size Contact	Contact Type	Mounting Option	Plating Option

Series

KF66X - High Density D-Subminiature Connector, Right Angle PCB Termination, 0.350" Footprint, with Ferrite

Shell Size-Contact Option

E - 15 Contacts

Contact Type

P - Pin Contact (Plug)

S - Socket Contact (Receptacle)

Mounting Option

N - With Boardlocks and #4-40 UNC Threaded Insert

NJ -With Boardlocks and #4-40 Jackscrews Installed

Plating Option

Blank - Gold Flash

30 - 30μ" Gold

Contact Kycon for VESA and Other Options