



## Main

Product Type	Power relay
Switch Function	DPDT
Contact Composition	2 NC + 2 NO

## Complementary

Input Current	25 A
Contacts Material	Silver alloy contacts
Minimum Switching Current	100 mA 5 V DC
Coil Resistance	100 Ohm
Input voltage	12 V DC
Drop-out Voltage Threshold	$\geq 0.1 U_c$ AC/DC
Rated Operational Current	25 A at 300 V AC (on resistive load) conforming to UL 5 A at 600 V AC (on resistive load) conforming to UL 13 A at 28 V DC (on resistive load) conforming to UL 22 A at 120 V AC (full load) conforming to UL 20 A at 277 V AC (ballast) conforming to IEC 25 A at 250 V AC-1 (NO/NC) conforming to IEC 15 A at 28 V DC-1 (NO/NC)
Power consumption in W	1.3 W DC
Power consumption in VA	2 VA AC
Voltage Range	$0.8 \dots 1.1 U_c$ DC
Maximum Switching Voltage	600 V AC
Motor Power HP	1.5 Hp 200/240 V AC 50/60 Hz 1 Hp 120...200V AC 50/60 Hz 1 hp 600 V AC 50/60 Hz
Connections Terminals	Quick
Mounting	Flange
Product Weight	2.96 oz (84 g)

## Environment

Ambient Air Temperature for Operation	-22...131 °F (-30...55 °C)
Ambient Air Temperature for Storage	-22...185 °F (-30...85 °C)
Product Certifications	CURus CSA CE
Electrical Durability	100000 Cycles resistive load 50000 cycles resistive DC load
Mechanical Durability	5000000 cycles
Dielectric Strength	2200 V AC between coil and contact 2200 V AC between poles 1600 V AC between contacts

## Ordering and shipping details

GTIN	3606480276811
Nbr. of units in pkg.	1
Package weight(Lbs)	2.96 oz (84.0 g)

## Packing Units

Unit Type of Package 1	PCE
Package 1 Height	2.90 in (7.36 cm)
Package 1 width	1.49 in (3.78 cm)
Package 1 Length	1.36 in (3.45 cm)
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Weight	29.63 oz (840.0 g)
Package 2 Height	1.57 in (4 cm)
Package 2 width	5.20 in (13.2 cm)
Package 2 Length	7.42 in (18.85 cm)
Unit Type of Package 3	S02
Number of Units in Package 3	60
Package 3 Weight	15.23 lb(US) (6.91 kg)
Package 3 Height	5.91 in (15 cm)
Package 3 width	11.81 in (30 cm)
Package 3 Length	15.75 in (40 cm)



## Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Nickel compounds, which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>

---

Connections and Wiring Diagrams

---

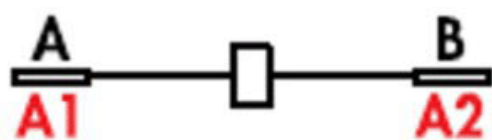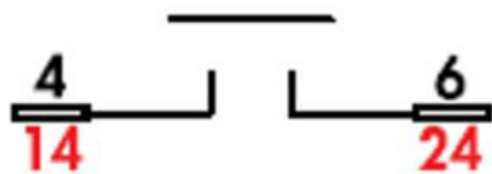


**SPST-NO-(DM)**

---

Connections and Wiring Diagrams

---

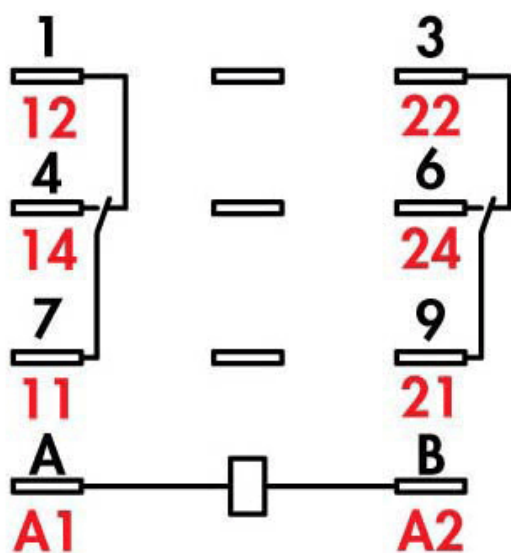

**DPDT**