

# Product data sheet

Specifications



Remote control, Harmony eXLhoist,  
standard, display, 6 motion push  
buttons, 6 auxiliary push buttons

ZART12D

**Product availability: Non-Stock - Not normally stocked in distribution facility**

## Main

|                           |   |
|---------------------------|---|
| Range of Product          | Harmony eXLhoist  |
| Product or Component Type | Hand-held remote control  |
| Device short name         | ZART  |
| Control Button Type       | 6 configurable motion push-button<br>6 configurable auxiliary push-button |

## Complementary

|                            |  |
|----------------------------|--|
| Material                   | Enclosure PC (polycarbonate)<br>Enclosure PBT (polybutylene terephthalate)<br>Cover PP (polypropylene)<br>Protective cover EPDM rubber |
| Function Available         | Accelerometer function<br>Vibrator function  |
| Display type               | LCD display 34 x 42 mm   |
| Operating Distance         | 50 m   |
| Mechanical robustness      | Free fall resistance 4.5 m IEC 60068-2-27  |
| Communication network type | Wireless bluetooth low energy  |
| Transmission frequency     | 2.4 GHz  |
| Maximum sensing distance   | 328.08 ft (100 m) in free field  |
| Response time              | < 300 ms full duplex   |
| Charging time              | 900 s  |
| Autonomy                   | 30 h   |
| Mechanical durability      | 5000000 cycles   |
| Service Life               | 5 year(s)  |
| Width                      | 3.9 in (100 mm)  |
| Height                     | 13.4 in (340 mm)   |
| Depth                      | 3.5 in (90 mm)   |
| Net Weight                 | 1.43 lb(US) (0.65 kg)  |

## Environment

|                 |   |
|-----------------|---|
| Radio agreement | FCC<br>ARIB<br>RSS<br>ICASA<br>ANATEL<br>SRRC |
|-----------------|---|

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

|                                       |   |
|---------------------------------------|---|
| IP degree of protection               | IP65  |
| NEMA degree of protection             | NEMA 4  |
| Ambient Air Temperature for Operation | -4...140 °F (-20...60 °C)                     |
| Ambient Air Temperature for Storage   | -4...113 °F (-20...45 °C)                     |
| Operating altitude                    | 0...6561.68 ft (0...2000 m)                   |
| Storage altitude                      | 0...9842.5 ft (0...3000 m)                    |
| Vibration resistance                  | 0.075 mm 10...55 Hz)IEC 60068-2-6             |
| Shock resistance                      | 100 gn IEC 60068-2-27                         |
| Relative humidity                     | 0...95 % -4...140 °F (-20...60 °C) operating  |
| Product Certifications                | C-tick<br>CSA<br>CE<br>JIS<br>KC<br>EAC<br>UL |

## Ordering and shipping details

|                   |               |
|-------------------|---------------|
| Category          | US10CS222479  |
| Discount Schedule | 0CS2          |
| GTIN              | 3606480610370 |
| Returnability     | Yes           |
| Country of origin | FR            |

## Packing Units

|                              |                         |
|------------------------------|-------------------------|
| Unit Type of Package 1       | PCE                     |
| Nbr. of units in pkg.        | 1                       |
| Package 1 Height             | 4.21 in (10.700 cm)     |
| Package 1 Width              | 4.02 in (10.200 cm)     |
| Package 1 Length             | 13.27 in (33.700 cm)    |
| Package weight(Lbs)          | 26.420 oz (749.000 g)   |
| Unit Type of Package 2       | S03                     |
| Number of Units in Package 2 | 4                       |
| Package 2 Height             | 11.81 in (30.000 cm)    |
| Package 2 Width              | 11.81 in (30.000 cm)    |
| Package 2 Length             | 15.75 in (40.000 cm)    |
| Package 2 Weight             | 7.683 lb(US) (3.485 kg) |



Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

## Environmental footprint

Environmental Disclosure

[Product Environmental Profile](#)

## Use Better

### Materials and Substances

|  |   |
|--|---|
| Packaging made with recycled cardboard | No  |
| Packaging without single use plastic   | No  |
| <a href="#">EU RoHS Directive</a>      | Pro-active compliance (Product out of EU RoHS legal scope)  |
| SCIP Number                            | 6e438e59-42d1-4633-bfe2-cb5ef607659b  |
| California proposition 65              | <b>WARNING:</b> This product can expose you to chemicals including: Nickel compounds, which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to <a href="#">www.P65Warnings.ca.gov</a> |


## Use Again

### Repack and remanufacture

|                     |  |
|---------------------|--|
| Circularity Profile | <a href="#">End of Life Information</a>  |
| Take-back           | No   |
| WEEE Label          | The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins. |

## Dimensions Drawings


## Dimensions

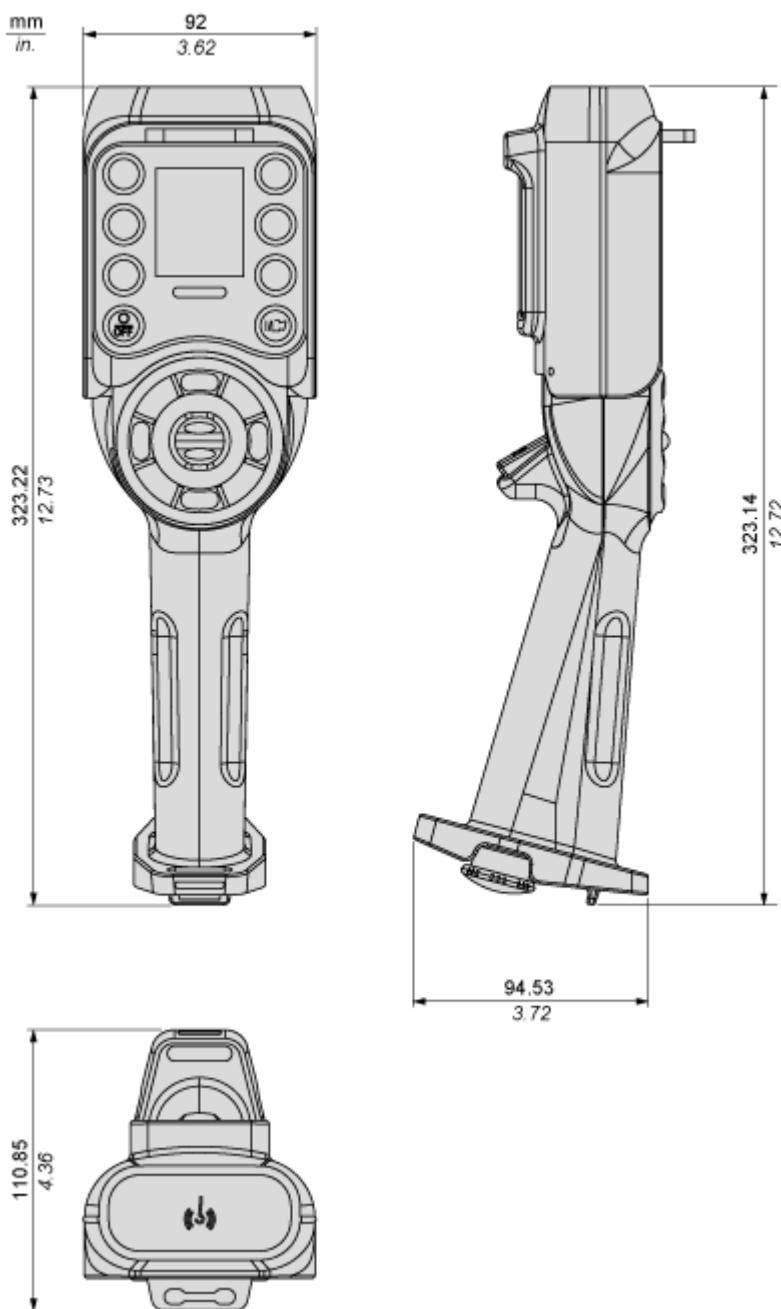

## Technical Illustration

### Dimensions

---

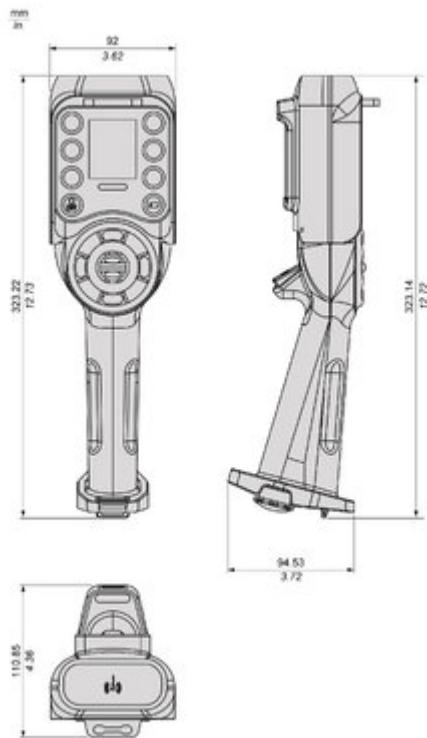

## Offer Marketing Illustration

## Product benefits / Features



## Offer Marketing Illustration

## Product benefits / Features

## Technical benefits

### ZAR Harmony Pocket remote

The Harmony Pocket Remote uses the worldwide free 2.4 GHz frequency to allow unrestricted operation.

Product certifications:  
CE, UL  
Radio certifications:  
FCC, IC

Users can integrate 3, 4, 6, 8 or 10 buttons according to their needs

IP 67 for the transmitter and IP 66 for the receiver



Image of product / Alternate images

Alternative

---







Image of product in real life situation

