


Product data sheet

Characteristics

8911DPSO13V06

Starter, Definite Purpose, nonreversing, 20A,
3 pole, 3 phase, 480 VAC coil, melting alloy
overload, open style

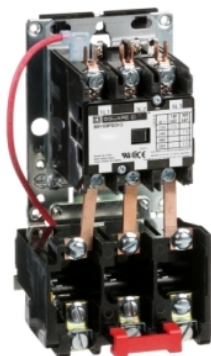

Main

Product	Definite Purpose Starter
Ampere Rating	20 A
Horsepower Rating	3 Hp 230 V AC, 1 phase 7.5 Hp 230 V AC, 3 phase 1.5 Hp 115 V AC, 1 phase 7.5 Hp 460 V AC, 3 phase 7.5 hp 575 V AC, 3 phase
Maximum Voltage Rating	600 V AC
Control Circuit Voltage	440 V AC 50 Hz 480 V AC 60 Hz
Phase	3 phase

Complementary

Enclosure Rating	Not rated (open device)
Locked Rotor Amperes	120 A 230 V AC 100 A 460 V AC 80 A 575 V AC
Number of Poles	3P
Range	DPS
Overload Type	Melting alloy
Number of Thermal Units	3

Ordering and shipping details

Category	21381-8911 DP
Discount Schedule	CP1
GTIN	785901025139
Nbr. of units in pkg.	1
Package weight(Lbs)	2.27 lb(US) (1.03 kg)
Returnability	Yes
Country of origin	CN

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	4.70 in (11.938 cm)
Package 1 width	4.70 in (11.938 cm)
Package 1 Length	7.70 in (19.558 cm)

Offer Sustainability

REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration

Contractual warranty

Warranty	18 months
----------	-----------