


Product data sheet

Characteristics

8965DPR34V02

Reversing Hoist Contactor, 30 A, 4P, 110/120 VAC 50/60 Hz coil, open style

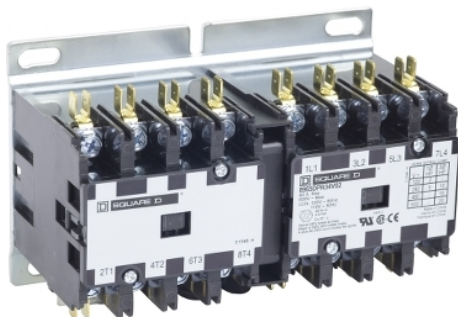

Main

Product or Component Type	Reversing Hoist Contactor
Line Rated Current	30 A
Maximum Horse Power Rating	2 Hp 115 V AC, 1 phase 5 Hp 230 V AC, 1 phase 10 Hp 230 V AC, 3 phase 15 Hp 460 V AC, 3 phase 15 hp 575 V AC, 3 phase

Complementary

Product Certifications	CSA UL Listed
[Ue] rated operational voltage	600 V AC
Poles description	4P
[Uc] control circuit voltage	110 V AC 50 Hz 120 V AC 60 Hz
Phase	3 phase
Range of Product	DPR

Ordering and shipping details

Category	21403-8965DPR1>DPR4 - 20A>40A REV HOIST
Discount Schedule	CP1
GTIN	785901025894
Returnability	Yes
Country of origin	CN

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	5.10 in (12.954 cm)
Package 1 Width	4.70 in (11.938 cm)
Package 1 Length	8.40 in (21.336 cm)
Package 1 Weight	3.42 lb(US) (1.551 kg)

Offer Sustainability

REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes

Contractual warranty

Warranty	18 months
----------	-----------