

Product data sheet

Specifications



Multisound siren, prewired, Harmony XVS, white colour, 0...105 dB, 43 tones, 120V AC

XVS14GMW

**Product availability: Non-Stock - Not normally stocked in
distribution facility**

Main

Range of Product	Harmony XVS
Product or Component Type	Multisound siren
Device short name	XVS

Complementary

Color	White
Material	PC (polycarbonate): back cover PC (polycarbonate)/ABS (acrylonitrile butadiene-styrene): front PC (polycarbonate)/ABS (acrylonitrile butadiene-styrene): back
Net Weight	2.6 lb(US) (1.2 kg)
Marking	CE
Mounting Support	Bracket
Fixing Mode	3 holes Ø 9 mm
[Uimp] rated impulse withstand voltage	4 kV
Current consumption	100 mA 120 V
Electrical connection	Cable 0.3...0.3 in (6.5...8.5 mm), 0.0005 in ² (0.33 mm ²) / AWG 22 signalling circuit Cable 0.3...0.3 in (6.5...8.5 mm), 0.0008 in ² (0.52 mm ²) / AWG 20 power circuit
Width	5.5 in (140 mm)
Height	4.5 in (114 mm)
Depth	8.8 in (223 mm)

Environment

Signalling type	43 tones siren
Standards	IEC 61000-6-2 IEC 61000-6-3 IEC 60947 EN 60947-5
Product Certifications	UL
Protective treatment	TC
Ambient Air Temperature for Storage	-31...158 °F (-35...70 °C)
Ambient Air Temperature for Operation	14...122 °F (-10...50 °C)
Overvoltage category	Class II conforming to IEC 61140
IP degree of protection	IP53 conforming to IEC 60529
[Us] rated supply voltage	120 V AC

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Noise level	0...105 dB continuous or intermittent tone)1 m
-------------	--

Ordering and shipping details

Category	US100XV22617
Discount Schedule	00XV
GTIN	3606480072048
Returnability	Yes
Country of origin	ID

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	6.10 in (15.49 cm)
Package 1 Width	6.30 in (16 cm)
Package 1 Length	11.00 in (27.94 cm)
Package 1 Weight	3.44 lb(US) (1.56 kg)
Unit Type of Package 2	S04
Number of Units in Package 2	6
Package 2 Height	11.81 in (30 cm)
Package 2 Width	15.75 in (40 cm)
Package 2 Length	23.62 in (60 cm)
Package 2 Weight	23.933 lb(US) (10.856 kg)
Unit Type of Package 3	PAL
Number of Units in Package 3	24
Package 3 Height	23.62 in (60 cm)
Package 3 Width	31.50 in (80 cm)
Package 3 Length	9.45 in (24 cm)
Package 3 Weight	83.917 lb(US) (38.064 kg)

Contractual warranty

Warranty	18 months
----------	-----------



Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Environmental footprint

[Environmental Disclosure](#)

[Product Environmental Profile](#)

Use Better

Materials and Substances

Packaging made with recycled cardboard

Yes

Packaging without single use plastic

Yes

[EU RoHS Directive](#)

Pro-active compliance (Product out of EU RoHS legal scope)

SCIP Number

Fe0ee3ab-dd49-4abe-bd8e-c49754e2c442

REACH Regulation

[REACH Declaration](#)

California proposition 65

WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

Use Again

Repack and remanufacture

[Circularity Profile](#)

[End of Life Information](#)


Take-back

No

Dimensions Drawings

Siren

Dimensions

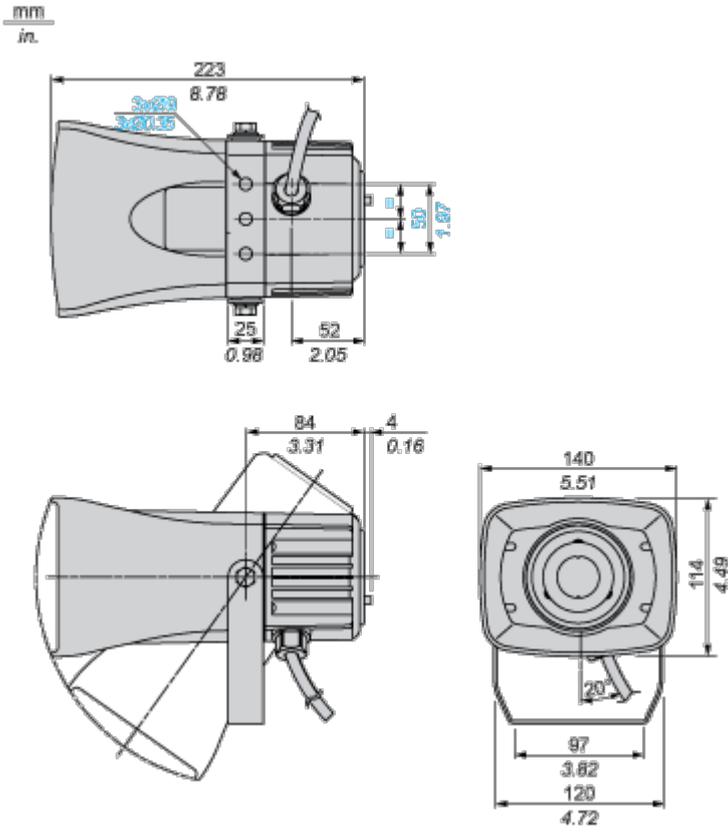

Technical Illustration

Dimensions

