


Product data sheet

Characteristics

8910DP12V02Y248

Contactor, Definite Purpose, 20A, 2 pole,
110/120 VAC 50/60 Hz coil, open, with cover

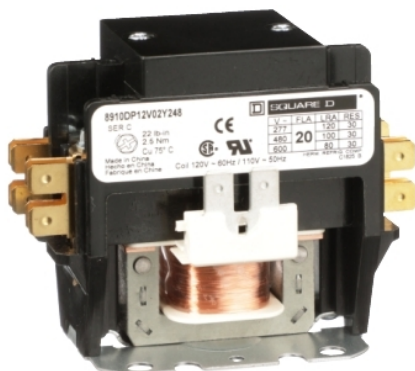

Main

Product or Component Type	Definite Purpose Contactor
Line Rated Current	20 A
Number of Poles	2P
Pole contact composition	2 NO
Range of Product	DP
Provided equipment	Terminal cover

Complementary

Maximum Horse Power Rating	1 Hp 115 V AC, 1 phase 2 hp 230 V AC, 1 phase
Locked rotor rated current	100 A 460 V AC 80 A 575 V AC 120 A 277 V AC
[Ue] rated operational voltage	600 V AC
[Uc] control circuit voltage	120 V AC 60 Hz 110 V AC 50 Hz
Phase	1 phase
Electrical Connection	Binder head Quick connect terminals

Environment

Product Certifications	UL Recognized CSA
------------------------	----------------------

Ordering and shipping details

Category	21352-8910 DP 12
Discount Schedule	CP1B
GTIN	785901397182
Returnability	Yes
Country of origin	CN

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	2.30 in (5.842 cm)
Package 1 Width	2.70 in (6.858 cm)
Package 1 Length	3.50 in (8.89 cm)
Package 1 Weight	10.08 oz (285.763 g)

Offer Sustainability

REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes

Contractual warranty

Warranty	18 months
----------	-----------