


Product data sheet

Characteristics

8911DPSO23V02

Starter, Definite Purpose, nonreversing, 25A,
3 pole, 3 phase, 110/120VAC 50/60Hz coil,
melting alloy overload, open style

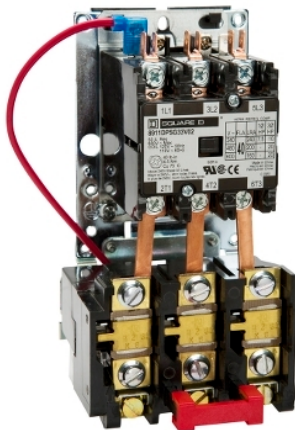

Main

Product	Definite Purpose Starter
Ampere Rating	25 A
Horsepower Rating	2 Hp 115 V AC, 1 phase 5 Hp 230 V AC, 1 phase 10 Hp 230 V AC, 3 phase 15 Hp 460 V AC, 3 phase 20 hp 575 V AC, 3 phase
Maximum Voltage Rating	600 V AC
Control Circuit Voltage	110 V AC 50 Hz 120 V AC 60 Hz
Phase	3 phase

Complementary

Enclosure Rating	Not rated (open device)
Locked Rotor Amperes	150 A 230 V AC 125 A 460 V AC 100 A 575 V AC
Number of Poles	3P
Range	DPS
Overload Type	Melting alloy
Number of Thermal Units	3

Ordering and shipping details

Category	21381-8911 DP
Discount Schedule	CP1
GTIN	785901116745
Returnability	Yes
Country of origin	CN

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	5.20 in (13.208 cm)
Package 1 Width	4.80 in (12.192 cm)
Package 1 Length	7.80 in (19.812 cm)
Package 1 Weight	2.25 lb(US) (1.021 kg)

Offer Sustainability

REACH Regulation	 REACH Declaration
EU RoHS Directive	Compliant  EU RoHS Declaration
Mercury free	Yes
China RoHS Regulation	 China RoHS Declaration
RoHS exemption information	 Yes

Contractual warranty

Warranty	18 months
----------	-----------