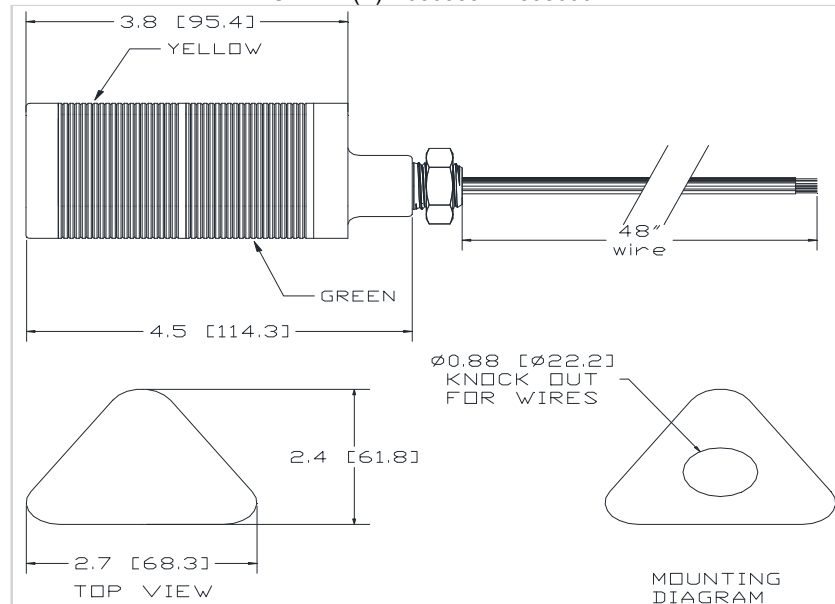


**Mallory Sonalert Products, Inc.**Part #: **JTC028-YG-CD****Sales Outline Drawing**Revision: **A****Specifications:**

Stack Number:	1	2			
LED Color:	YELLOW	GREEN			
LED Operation:	Continuous	Continuous			
Connection Wires:	Yellow and Brown	Green and Brown			
LED Current Draw:	<60 mA	<40 mA			
Rated Voltage:	24 VAC/DC				
Operating Voltage:	20-28 VAC/DC				
Total Max Current:	<100mA				
Operating Temperature:	-25° ~ +60°C				
Lens Color:	Transparent - matching LED stack color				
Material:	Lexan CFR7431				
Mounting Method:	Direct Mount using 1/2" NPT Stainless Steel Pipe and Nut				
Weight Typical (g):	210				
NEMA 12:	Approved				
Options:	Please contact factory.				

Dimensions: Inches (mm)**cUL Recognized CE Certified****ROHS Compliant**

PATENT NUMBER(S) 10309594 D898600

**LED OPERATION:** CONNECT STACK COLOR WIRE TO POWER AND BROWN WIRE TO POWER.