


## 2-Conductor Bulk Speaker Wire, Plenum and Riser Rated, 16 AWG, 250 ft. (76.2 m)

MODEL NUMBER: A240-002-16P

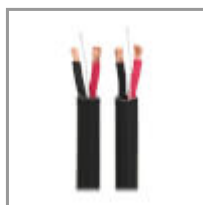

Supports a wide range of low-voltage installations, including audio, access control, alarm and LED lighting.

### Features

#### 16 AWG Speaker Wire Recommended for Audio Installations and LED Lighting

This stranded two-conductor flame-retardant power-limited wiring supports a wide range of low-voltage installations, including audio, access control, alarm and LED lighting. The UL-rated A240-002-16P is ideal for connecting LED lights in commercial or residential projects or speakers, amplifiers and receivers in a top-shelf audio installation.

#### Plenum Rated for Flexibility in Installation

The A240-002-16P carries a CMP rating, indicating a plenum-rated wire that can be routed inside walls, above suspended ceilings or through open air spaces to give you more choices in creating your installation. This 250-foot (76.2-meter) reel is lightweight for simple transportation and allows you to pull out of the box exactly the amount of wire you need.

### Highlights

- 250 ft. reel of stranded 2-conductor flame-retardant power-limited speaker wire
- Recommended for audio, access control, alarm and LED lighting installations
- Plenum rated for installations within walls or above ceilings

### Package Includes

2-Conductor Speaker Wire, 250 ft. (76.2 m)

## Specifications

| OVERVIEW             |              |
|----------------------|--------------|
| UPC Code             | 037332290618 |
| VIDEO                |              |
| HDR Support          | No           |
| 3D Video Supported   | No           |
| DisplayPort Alt Mode | No           |
| CONNECTIONS          |              |
| Side A - Connector 1 | BARE WIRE    |
| Side B - Connector 1 | BARE WIRE    |



Powering Business Worldwide

TRIPP LITE  
SERIES

|                                              |                               |
|----------------------------------------------|-------------------------------|
| Connector Type                               | Bare Wire                     |
| Latching or Gripping Connector               | No                            |
| <b>PHYSICAL</b>                              |                               |
| Color                                        | Black                         |
| Cable Jacket Color                           | Black                         |
| Cable Jacket Material                        | PVC                           |
| Cable Jacket Rating                          | CMP                           |
| Cable Outer Diameter (OD)                    | 5.1MM                         |
| Number of Conductors                         | 2                             |
| Wire Type                                    | Stranded                      |
| Wire Gauge (AWG)                             | 16                            |
| Cable Length (ft.)                           | 250                           |
| Cable Length (m)                             | 76.22                         |
| Shipping Dimensions (hwd / in.)              | 6.69 x 7.48 x 7.48            |
| Shipping Weight (kg)                         | 4.20                          |
| Unit Dimensions (hwd / in.)                  | 6.000 x 7.480 x 7.480         |
| <b>ENVIRONMENTAL</b>                         |                               |
| Operating Temperature Range                  | 14° to 122°F (-10° to 50°C)   |
| Storage Temperature Range                    | 5° to 140°F (-15° to 60°C)    |
| Relative Humidity                            | 10% TO 90% RH, NON-CONDENSING |
| <b>COMMUNICATIONS</b>                        |                               |
| EDID Compatible                              | No                            |
| Consumer Electronics Control (CEC) Supported | No                            |
| <b>FEATURES &amp; SPECIFICATIONS</b>         |                               |
| EMI/RFI Line Noise Protection                | No                            |
| Integrated/Removable Cable                   | No                            |
| MST Support                                  | No                            |
| Antibacterial                                | No                            |
| Fully Molded Connector Ends                  | No                            |
| Ohms                                         | No                            |
| Integral Strain Relief                       | No                            |
| Impedance-Matched Twisted-Pair Construction  | No                            |
| Scaler Function                              | No                            |

|                                     |                                |
|-------------------------------------|--------------------------------|
| IP67 Rated                          | No                             |
| Armored Cable                       | No                             |
| Driver Required                     | No                             |
| DIN Mountable                       | No                             |
| STANDARDS & COMPLIANCE              |                                |
| Product Compliance                  | CE (Europe); REACH; RoHS; UKCA |
| WARRANTY & SUPPORT                  |                                |
| Product Warranty Period (Worldwide) | Lifetime limited warranty      |

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.