


Quad-Display Desktop Monitor Stand for 13" to 27" Flat-Screen Displays

MODEL NUMBER: DDR1327MQ

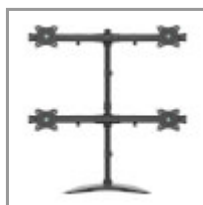

Mounts up to four 13 to 27 in. monitors on a single base to free up valuable space on your home or office desk, table or work area.

Features

Mounts Up to 4 Monitors on a BaseFrees up valuable workspace on your desk, table or workstationFits most flat-panel displays from 13 to 27 in.Mounts adjust independently for viewing angleIdeal for home and office use

Convenient One-Touch Adjustment180° swivel and -45° to +45° tilt capability provides comfortable viewingFull 360° rotation for viewing in portrait or landscape orientation

Durable Metal ConstructionEach mount supports up to 17.6 lbs (7.9 kgs)Scratch-resistant powder-coated finish blends with any décorMounting hardware included

VESA ComplianceSupports the following VESA mounting hole patterns: 75 x 75 mm, 75 x 100 mm, 100 x 75 mm, and 100 x 100 mm

Highlights

- Monitor stand with heavy-duty base remains stable on your desk during adjustment
- -45° to +45° tilt, -15° to +15° swivel and 360° rotation helps you find the perfect angle
- Durable steel construction blends into any décor and supports up to 17.6 lbs (7.9 kgs) per monitor
- Display cables attach to pole to reduce clutter and keep cords organized
- VESA compliance ensures compatibility with 75x75 and 100x100 mounting patterns

Applications

- Lift as many as 4 monitors above your standing desk or workstation to free up valuable surface space
- Swivel, tilt and/or rotate your screens for the most comfortable viewing angle

System Requirements

- Up to 4 flat-screen monitors from 13 to 27 in. with 75 mm or 100 mm VESA mounting holes

Package Includes

- (4) VESA plate assemblies
- Upper pole
- Lower pole
- Pole connector
- Base
- (4) Mount arms
- (4) Arm cable guides
- (2) Pole cable guides
- (2) Locking head assemblies
- (4) End caps
- Base collar
- Hex key, 3 mm
- Hex key, 4 mm
- Hex key, 6 mm
- (4) Flat-head screws
- (16) M4 x 12 screws
- (16) M5 x 12 screws
- (16) D5 washers



Powering Business Worldwide

TRIPP LITE
SERIES

- Owner's manual

Specifications

OVERVIEW	
UPC Code	037332257833
Device Compatibility	Monitor/HDTV
PHYSICAL	
Color	Black
Material of Construction	Steel
VESA Pattern (mm)	100x100; 100x75; 75x100; 75x75
Motion	Full
Mounting Location	Desktop
Degrees of Motion	-45/+45 Tilt; 180 Swivel; 360 Rotate
Minimum Screen Size (in.)	13
Minimum Screen Size (cm)	33
Maximum Screen Size (in.)	27
Maximum Screen Size (cm)	68.6
Maximum Weight Capacity (lbs.)	17.6
Maximum Weight Capacity (kg)	8
Number of Displays	4
Shipping Dimensions (hwd / in.)	18.50 x 13.20 x 5.40
Shipping Dimensions (hwd / cm)	46.99 x 33.53 x 13.72
Shipping Weight (lbs.)	21.04
Shipping Weight (kg)	9.54
Unit Dimensions (hwd / in.)	32.200 x 31.700 x 12.400
Unit Dimensions (hwd / cm)	81.8 X 80.5 X 31.5
Unit Weight (lbs.)	6.7
Unit Weight (kg)	3.04
Assembly Required	Yes
FEATURES & SPECIFICATIONS	
Antimicrobial	No
Cord Management	No
Tools Necessary	Yes



Powering Business Worldwide

TRIPP LITE
SERIES

Security Lock	No
STANDARDS & COMPLIANCE	
Product Compliance	RoHS; RoHS3; REACH
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	5-year limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.