


USB-A to Right-Angle Lightning Sync/Charge Cable, MFi Certified - White, M/M, USB 2.0, 6 ft. (1.83 m)

MODEL NUMBER: M100-006-LRA-WH

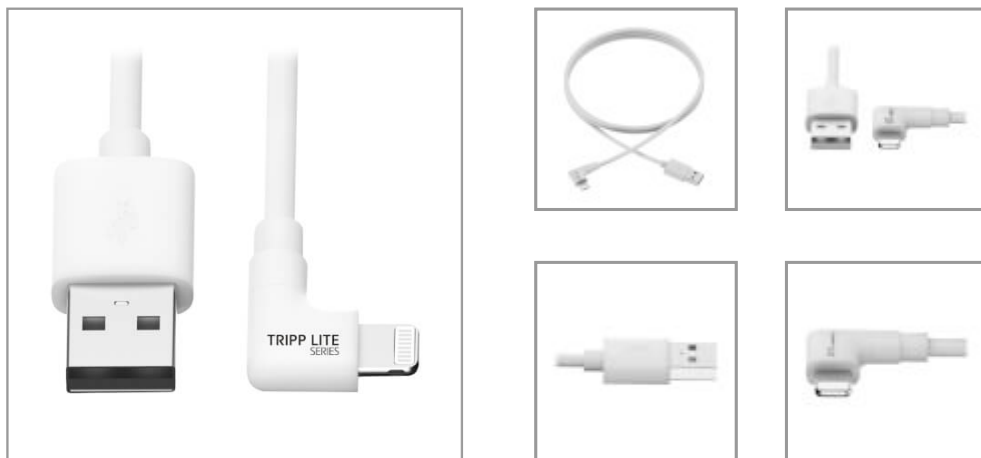

This USB Type-A to Lightning cable connects your 8-pin iPhone, iPad or iPod device to the USB port on your computer or wall charger.

Features

Effortlessly Sync and Charge Your Apple Devices This USB to Lightning cable lets you connect your iPhone, iPad, or iPod to sync your device with your media library and charge it. Portable and convenient, you can easily take this cable anywhere. Keep one handy in your car, your bag, briefcase and anywhere else a charger will come handy.

MFi-Certified for Broad Device Compatibility The six-foot Lightning cable is MFi-certified for use with the latest generation of iPhone, iPad and iPod devices. The USB-A plug connects to any computer or wall charger with a USB port.

Reversible Lightning Connector Right Angle Plugs in Either Direction The fumble-free reversible Lightning plug connects in either direction and the angled connector provides a natural fit for ports in hard-to-reach locations. The six-foot cord lets you easily connect to a USB port on most computers.

Highlights

- Syncs and charges your iPhone, iPad or iPod device quickly and easily
- Connects to USB-A port on computer or wall charger
- Angled Lightning connector is ideal for tight spaces
- MFi-certified for broad compatibility with your Apple iPhone, iPad or iPod
- Reversible Lightning connector plugs into your Apple device in either direction

Applications

- Charge and sync your Apple iPhone, iPad or iPod using the USB-A port on your computer or a wall charger up to 6 ft. away
- Transfer photos and other important files between an external hard drive and your Apple device

System Requirements

- Computer, laptop or charger with USB-A port
- Most current iPhone, iPad and iPod devices

Package Includes

M100-006-LRA-WH Right-Angle Lightning Cable, USB Type A To Lightning, 6 ft.

Specifications

OVERVIEW	
UPC Code	037332222060
Technology	Lightning; USB 2.0 (High Speed)
Cable Type	Passive
INPUT	
Maximum Input Amps	2
POWER	



Powering Business Worldwide

TRIPP LITE
SERIES

USB Power Delivery (PD) Charging Support	No
CONNECTIONS	
Side A - Connector 1	USB A (MALE)
Side B - Connector 1	LIGHTNING (MALE) - RIGHT ANGLE
Connector Plating	Nickel
Contact Plating	Gold
Connector Style	Angled
CHARGING	
Total Charging Watts	12
PHYSICAL	
Material of Construction	PVC
Cable Jacket Color	White
Cable Jacket Material	PVC
Cable Jacket Rating	VW-1
Cable Outer Diameter (OD)	3.2mm
Wire Gauge (AWG)	28/21
Cable Length (ft.)	6
Cable Length (m)	1.83
Cable Length (in.)	72
Shipping Dimensions (hwd / in.)	0.91 x 5.20 x 2.60
Shipping Weight (lbs.)	0.10
Shipping Weight (kg)	0.05
Unit Dimensions (hwd / in.)	0.910 x 5.200 x 2.600
Unit Packaging Type	Box
ENVIRONMENTAL	
Operating Temperature Range	-4° to 140°F (-20° to 60°C)
Storage Temperature Range	-4° to 176°F (-20° to 80°C)
Operating Humidity Range	0% to 90% RH, Non-Condensing
Storage Humidity Range	0% to 90% RH, Non-Condensing
Power Provided to Connected Device(s)	12W (5V/2.4A)
FEATURES & SPECIFICATIONS	
USB Specification	USB 2.0 (up to 480 Mbps)



Powering Business Worldwide

TRIPP LITE
SERIES

Data Transfer Rate	480 Mbps
Angled Plug	Yes
STANDARDS & COMPLIANCE	
Product Certifications	MFi
Product Compliance	RoHS; REACH; UKCA
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	2-year limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.