


24-Port 1U Rack-Mount Shielded Blank Keystone/Multimedia Patch Panel, RJ45 Ethernet, USB, HDMI, Cat5e/6

MODEL NUMBER: N062-024-KJ-SH

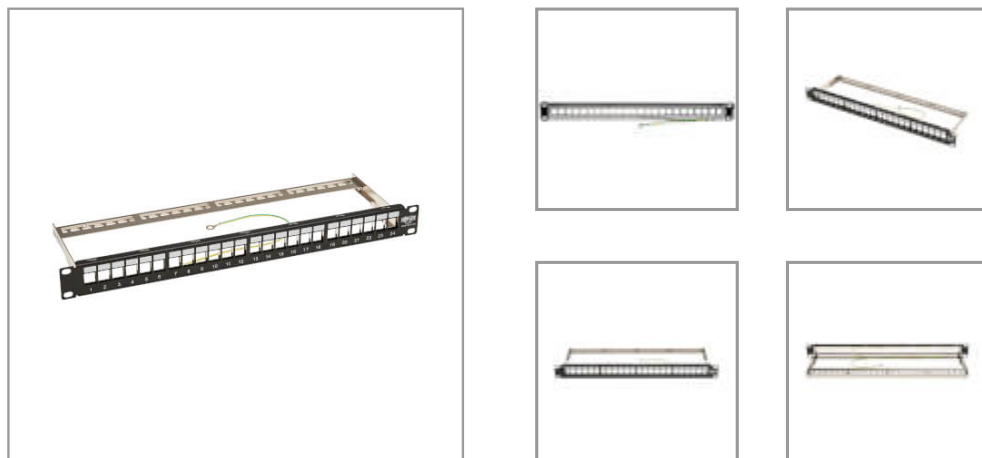

Manages and organizes input and output cable connections in your network. Customizable solution for a variety of applications, including Ethernet, voice, audio/video and USB.

Description

The N062-024-KJ-SH 24-Port 1U Rack-Mount Shielded Blank Keystone/Multimedia Patch Panel manages and organizes the cabling in your network. The 24 blank cutouts accommodate all keystone jacks, including RJ45 Ethernet, HDMI audio/video, voice and USB applications. The rear cable manager keeps cables neat, tidy and efficiently organized on the back of the panel. Ports are clearly numbered to help you identify connections. Mounts easily into 1U of an EIA-standard 19-inch two-post rack or wall-mount rack enclosure. Made from fully shielded, heavy-duty steel. Grounding wire included.

Features

Manages and Organizes a Wide Variety of Cabling 24 blank cutouts accommodate most keystone jacks in the market
For use with RJ45 Ethernet, HDMI audio/video, voice, USB and other applications
Ports are numbered for easy connection identification
Fully shielded, heavy-duty steel construction

Cable Manager on Rear Keeps cabling neat, tidy and organized

Quick, Easy Installation Mounts easily into 1U of EIA-standard 19 in. 2-post rack or wall-mount rack enclosure
Includes grounding wire

Specifications

OVERVIEW	
UPC Code	037332193612
Product Type	Rackmount
Technology	Cat5/5e; Cat6; Cat6a; DisplayPort; HDMI; USB 2.0 (High Speed)
CONNECTIONS	

Highlights

- 24 blank cutouts compatible with all keystone jacks
- Fully shielded, heavy-duty steel construction
- Rear cable manager keeps cables organized
- Numbered ports for easy connection identification
- Mounts into 1U of EIA-standard 19 in. 2-post or wall-mount rack

Package Includes

- N062-024-KJ-SH 24-Port 1U Rack-Mount Shielded Blank Keystone/Multimedia Patch Panel
- Grounding wire



Powering Business Worldwide

TRIPP LITE
SERIES

Number of Ports	24
Side A - Connector 1	KEYSTONE JACK CUTOUT
Side B - Connector 1	KEYSTONE JACK CUTOUT
PHYSICAL	
Color	Black
Shipping Dimensions (hwd / in.)	2.20 x 6.20 x 19.70
Shipping Dimensions (hwd / cm)	5.59 x 15.75 x 50.04
Shipping Weight (lbs.)	2.40
Shipping Weight (kg)	1.09
Unit Dimensions (hwd / in.)	3.300 x 19.000 x 0.500
Panel Style	Blank
FEATURES & SPECIFICATIONS	
IP68 Rated	No
IP20 Rated	No
STANDARDS & COMPLIANCE	
Product Compliance	RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty
Warranty Details	LIFETIME LIMITED

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.