


3-Slot Power Cord, NEMA 5-15P to C5 - Laptop/Notebook, 10A, 125V, 18 AWG, 3 ft. (0.91 m), Black

MODEL NUMBER: P013-003

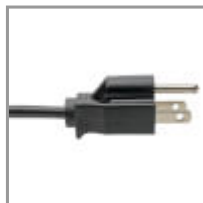

Laptop power cord connects your notebook or laptop with a 3-slot C6 power inlet to an AC outlet.

Features

Laptop Power Cable Connects Notebook Computers to an AC Outlet This NEMA 5-15P to C5 power cord is designed for connecting a notebook computer, laptop or other device with a three-slot C6 inlet to an AC wall outlet, surge protector, UPS system or PDU. It also powers some portable projectors, desktop computers and LG LCD televisions. The three-foot length helps reduce cable clutter and minimize the risk of tripping.

Highlights

- Recommended for powering notebook computers and laptops with C6 inlets
- 3-ft. (0.91 m) length allows flexibility in placing devices, while avoiding cable clutter
- Ideal replacement for a worn-out or missing laptop power cable

Applications

- Connect a laptop or notebook computer to a surge protector up to 3 ft. away in your workstation
- Extend an existing power connection up to 3 ft. to more easily place a device or reach a power source
- Provide a high-quality replacement for a worn-out or missing laptop power cord

Package Includes

- P013-003 3-Slot Power Cord, NEMA 5-15P to C5 - 6 ft., Black

Specifications

| OVERVIEW | |
|-----------------------------|---|
| UPC Code | 037332185907 |
| Device Compatibility | Laptop; Computer; Projector; Monitor/HDTV; UPS; PDU |
| Country/Region | North America |
| INPUT | |
| Maximum Input Amps | 10 |
| Voltage Compatibility (VAC) | 125 |
| CONNECTIONS | |
| Side A - Connector 1 | NEMA 5-15P |
| Side B - Connector 1 | IEC-320-C5 |
| PHYSICAL | |



Powering Business Worldwide

TRIPP LITE
SERIES

| | |
|--------------------------------------|-----------------------------|
| Plug Color | Black |
| Cable Jacket Color | Black |
| Cable Jacket Material | PVC |
| Cable Jacket Rating | VW-1 |
| Power Cord Jacket Type | SVT |
| Cable Outer Diameter (OD) | 6.3mm |
| Number of Conductors | 3 |
| Wire Gauge (AWG) | 18 |
| Wire Gauge (OD - mm ²) | 0.82 |
| Cable Length (ft.) | 3 |
| Cable Length (m) | 0.91 |
| Shipping Dimensions (hwd / in.) | 8.86 x 12.80 x 0.50 |
| Shipping Dimensions (hwd / cm) | 22.50 x 32.51 x 1.27 |
| Shipping Weight (lbs.) | 0.24 |
| Shipping Weight (kg) | 0.11 |
| ENVIRONMENTAL | |
| Operating Temperature Range | -4° to 140°F (-20° to 60°C) |
| Storage Temperature Range | -4° to 140°F (-20° to 60°C) |
| Operating Humidity Range | 10% to 65% RH |
| Storage Humidity Range | 10% to 65% RH |
| FEATURES & SPECIFICATIONS | |
| Antibacterial | No |
| Angled Plug | No |
| High Voltage | No |
| Locking Plug | No |
| Coiled Power Cord | No |
| STANDARDS & COMPLIANCE | |
| Product Certifications | cUL Listed; UL Listed |
| Product Compliance | RoHS |
| WARRANTY & SUPPORT | |
| Product Warranty Period (Worldwide) | Lifetime limited warranty |



Powering Business Worldwide

TRIPP LITE
SERIES

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.