


12-Outlet Power Strip with Surge Protection, 15 ft. (4.57 m) Cord, 1050 Joules, 36 in. length

MODEL NUMBER: **SS3612**

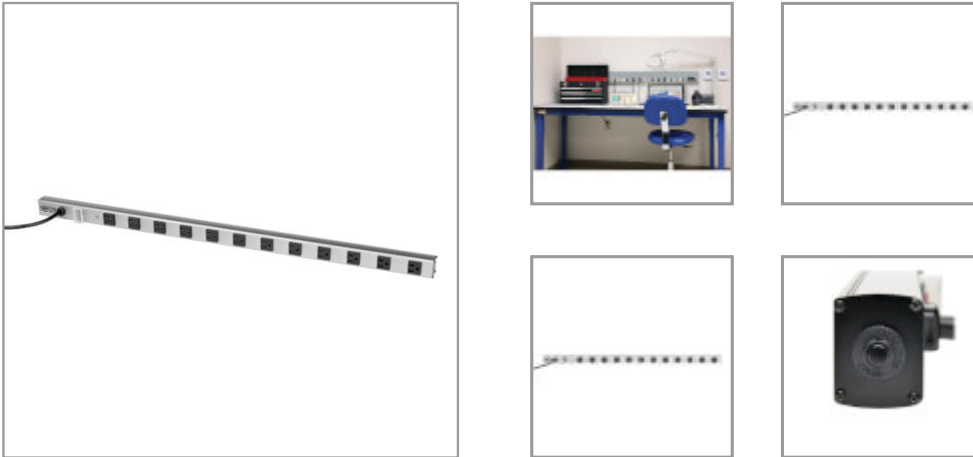

Highlights

- 12 outlets
- 15-ft. (4.57 m) cord
- 36-in. length
- 1050-joule rating

Package Includes

- SS3612 Power Strip/Surge Suppressor
- Set of adjustable mounting clips
- Warranty information
- Instruction manual

Description

The SS3612 power strip with AC surge suppression offers a convenient method of horizontal or vertical power distribution in equipment racks, computer rooms, workbenches, raceways and more. Includes 12 NEMA 5-15R outlets with 2.48-in. center-to-center spacing, 15-ft. (4.57 m) AC line cord and adjustable mounting clips for installation in a wide variety of applications. Protects connected equipment from transient surges and line noise with built-in surge suppression rated at 1050 joules. This corded, multi-outlet strip reduces cabling clutter and enables the connection of multiple electrical devices to a single AC wall socket. Features rugged all-metal housing, lighted power switch with transparent guard to prevent accidental shutoff, 15A resettable circuit breaker and attractive gray housing with black output receptacles.

PLUG/OUTLETS: Input: NEMA 5-15P Output: 12 NEMA 5-15R

ELECTRICAL: 120V AC, 50/60Hz, 15A (Requires standard NEMA 5-15R wall receptacle)

FORMAT: 3-ft. corded vertical/raceway power distribution strip

SURGE SUPPRESSION: 1050 joules

Features

- 3-ft. power strip with AC surge suppression offers a convenient method of horizontal or vertical power distribution in equipment racks, computer rooms, workbenches, raceways and more
- Protects connected equipment from transient surges and line noise with built-in surge suppression rated at 1050 joules
- 12 NEMA 5-15R outlets with 2.48-in. center-to-center spacing
- 15-ft. (4.57 m) AC line cord
- Adjustable mounting clips for installation in a wide variety of applications
- Corded, multi-outlet strip reduces cabling clutter and enables the connection of multiple electrical devices to a single AC wall socket
- Rugged all-metal housing
- Lighted power switch with transparent guard to prevent accidental shutoff
- 15A resettable circuit breaker
- Attractive gray housing with black output receptacles

Specifications



Powering Business Worldwide

TRIPP LITE
SERIES

| OVERVIEW | |
|------------------------------------|--|
| UPC Code | 037332186409 |
| INPUT | |
| Nominal Input Voltage(s) Supported | 120V AC |
| Recommended Electrical Service | 120V |
| Input Cord Gauge (AWG) | 14 |
| Voltage Compatibility (VAC) | 120 |
| Maximum Surge Amps | 22000 |
| Input Plug Type | NEMA 5-15P |
| Input Cord Details | SJT |
| Input Cord Length (ft.) | 15 |
| Right-Angle Plug | No |
| Input Cord Length (m) | 4.57 |
| Integrated Cord Clip | No |
| OUTPUT | |
| Frequency Compatibility | 60 Hz |
| Output (Watts) | 1800 |
| Output Receptacles | (12) 5-15R |
| Circuit Breaker (amps) | 15 |
| Outlet Spacing | 2.48-in. center-to-center spacing |
| USER INTERFACE, ALERTS & CONTROLS | |
| Diagnostic LED(s) | No |
| Switches | Combination AC circuit breaker and lighted 2-position power switch controls power to all outlets |
| Locking Switch Cover | Transparent locking switch cover |
| SURGE / NOISE SUPPRESSION | |
| AC Suppression Joule Rating | 1050 |
| UL1449 Let Through Rating | 500V UL verified |
| Automatic Shut-Off | No |
| DATALINE SURGE SUPPRESSION | |
| Cable (Coax) Protection | No |
| Network (Ethernet) Protection | No |
| Telephone/DSL Protection | No |



Powering Business Worldwide

TRIPP LITE
SERIES

| PHYSICAL | |
|--|---|
| Power Cord Color | Black |
| Housing Color | Silver |
| Mounting Holes or Slots | No |
| Outlets Measurement (Center to Center) | 2.48 |
| Receptacle Color | Black |
| Shipping Dimensions (hwd / in.) | 2.50 x 4.60 x 39.80 |
| Shipping Dimensions (hwd / cm) | 6.35 x 11.68 x 101.09 |
| Shipping Weight (lbs.) | 3.90 |
| Shipping Weight (kg) | 1.77 |
| Unit Dimensions (hwd / in.) | 1.250 x 1.620 x 36.000 |
| Unit Dimensions (hwd / cm) | 3.18 x 4.11 x 91.44 |
| Unit Weight (lbs.) | 3.19 |
| Unit Weight (kg) | 1.45 |
| Outlet Spacing | 2.48-in. center-to-center spacing |
| Mounting Details | Set of adjustable mounting clamps |
| FEATURES & SPECIFICATIONS | |
| Rotatable Outlets | No |
| Antimicrobial | No |
| Mounting Accessory Included | Yes |
| STANDARDS & COMPLIANCE | |
| Product Certifications | cUL Listed; UL 1449; UL 1363; UL Listed |
| Product Compliance | RoHS |
| WARRANTY & SUPPORT | |
| Product Warranty Period (Worldwide) | Lifetime limited warranty |

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.