


Protect It! 8-Outlet Computer Surge Protector, 8 ft. (2.43 m) Cord, 3150 Joules, Tel/Modem/Fax Protection, TAA

MODEL NUMBER: TLP808TELTAA

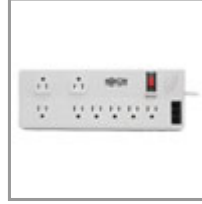

Highlights

- Compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases
- 8 outlets / 8-ft. (2.43 m) cord
- 3150 joule rating
- Modem/fax surge protection

Package Includes

- TLP808TELTAA Surge Suppressor
- 6-ft. (1.83 m) telephone cord
- Instruction manual with warranty information

Description

The TLP808TELTAA surge suppressor is compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases. It has eight outlets, an 8-foot (2.4-meter) cord with a space-saving right-angle plug, and diagnostic LEDs. The unit has a surge suppression rating of 3150 joules to handle the strongest surges. Built-in RJ11 jacks prevent surges from damaging your modem/fax/phone equipment.

Features

- Compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases
- 8 outlets with integrated child safety covers
- 8-ft. (2.43 m) cord with space-saving right-angle plug
- Built-in RJ11 jacks (1 in/2 out) prevent surges from damaging your modem/fax/phone equipment; 6-ft. (1.83 m) telephone cord included
- Surge suppression rating: 3150 joules
- Automatic shutoff permanently cuts power to outlets if protection circuit is incapacitated, preventing equipment damage and indicating replacement is required
- EMI/RFI noise filtering
- Can accommodate up to 3 transformers without blocking remaining outlets
- \$150,000 Ultimate Lifetime Insurance (U.S., Canada, and Puerto Rico only)
- Diagnostic LEDs indicate protection present & ground present
- Keyhole supports for wall mounting
- Lighted power switch

Specifications

OVERVIEW	
UPC Code	037332159267



Powering Business Worldwide

TRIPP LITE
SERIES

INPUT	
Nominal Input Voltage(s) Supported	120V AC
Recommended Electrical Service	120V (110-125V)
Input Cord Gauge Type	14 gauge; SJT
Input Cord Gauge (AWG)	14
Voltage Compatibility (VAC)	120
Input Plug Type	NEMA 5-15P
Input Cord Details	SJT
Input Cord Length (ft.)	8
Right-Angle Plug	Yes
Input Cord Length (m)	2.44
Integrated Cord Clip	No
OUTPUT	
Frequency Compatibility	60 Hz
Output (Watts)	1800
Output Receptacles	(8) 5-15R
Circuit Breaker (amps)	15
Transformer Accommodation	(6) Yes
Outlet Orientation	Single row of 5, plus a second row of 3 for transformer accommodation
Right-Angle Outlets	No
Outlet Safety Covers Detail	Includes built-in sliding outlet safety covers
USER INTERFACE, ALERTS & CONTROLS	
Diagnostic LED(s)	Yes
Switches	Combination AC circuit breaker and 2-position red illuminated on/off power switch
Diagnostic LED Details	Built-in LEDs confirm suppressor "protection present" (green) and "grounded" (red) status
SURGE / NOISE SUPPRESSION	
AC Suppression Joule Rating	3150
AC Suppression Response Time	< 1 ns
Protection Modes	Includes full normal mode (H-N) and common mode (N-G / H-G) line suppression
UL1449 Let Through Rating	400 L-N, 500 L-G, 500 N-G
EMI / RFI Filtering	Up to 40 dB
Automatic Shut-Off	Yes
DATALINE SURGE SUPPRESSION	



Powering Business Worldwide

TRIPP LITE
SERIES

Telephone/DSL Protection Details	1 line
Cable (Coax) Protection	No
Network (Ethernet) Protection	No
Telephone/DSL Protection	Yes
PHYSICAL	
Material of Construction	Plastic
Power Cord Color	Light Gray
Housing Color	Light Gray
Mounting Holes or Slots	Yes
Receptacle Color	Light gray
Shipping Dimensions (hwd / in.)	11.65 x 2.13 x 7.56
Shipping Dimensions (hwd / cm)	29.59 x 5.41 x 19.20
Shipping Weight (lbs.)	2.11
Shipping Weight (kg)	0.96
Unit Dimensions (hwd / in.)	10.500 x 3.900 x 2.200
Unit Dimensions (hwd / cm)	9.8 x 5.6 x 26.6
Unit Weight (lbs.)	1.69
Unit Weight (kg)	0.77
Outlet Spacing	1.122-in. center-to-center spacing
Form Factor Details	Strip
FEATURES & SPECIFICATIONS	
Additional Information	Pair of phone line output jacks serve as a line splitter to enable the protection of two devices sharing a single dialup phone line
Rotatable Outlets	No
Antimicrobial	No
STANDARDS & COMPLIANCE	
Product Certifications	CAN/CSA-C22.2 No. 269.3 (Canada); CAN/CSA-C22.2 No. 308 (Canada); cUL Listed; NOM (Mexico); UL 1449; UL 497A; UL 1363; UL Listed
Product Compliance	FCC Part 68; RoHS; Trade Agreements Act (TAA)
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty
Connected Equipment Insurance (U.S., Canada & Puerto Rico)	\$150,000 Ultimate Lifetime Insurance



Powering Business Worldwide

TRIPP LITE
SERIES

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.