



Quality Products. Service Excellence.


# Partial Height Door Support CPDS Series

For use with the C2 cabinet series only.

## Features



- Allows partial height flush door installation.
- Requires drilling of rack frame
- Occupies 1.75" (1U) of panel height
- Door support is 0.75" deep
- Constructed of 14 gauge steel.
- Finished in textured RAL9005 black powder paint coat.
  - Complies with the Greenguard guidelines for indoor air quality.
- TAA-compliant for GSA Schedule purchases.
- RoHS and REACH compliant.
- Manufactured in North America.

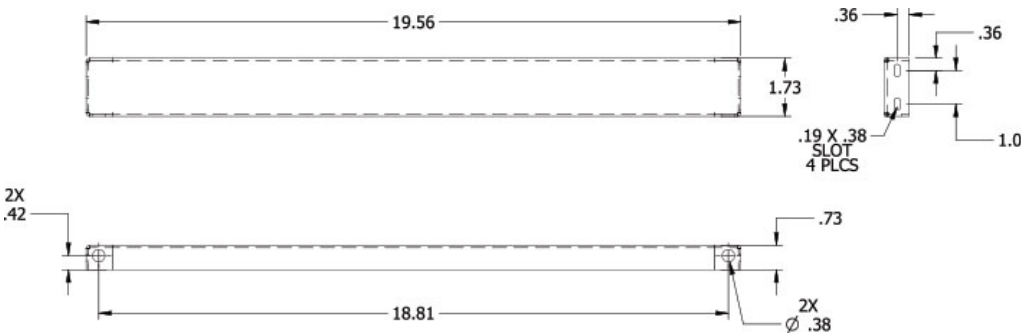

Part No.	Overall Dimensions			Mounting Dimensions		Rack Units
	Height	Width	Depth	Height	Width	
CPDS19BK1	1.73	19.56	0.73	1.75	19.00	1U

Data subject to change without notice