




*Quality Products. Service Excellence.*

## Type 4X Stainless Steel Two Door Wallmount Enclosure *HN4 WM SS*

*Series*

Continuous Hinge Door with Handle

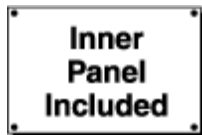

### Application

- Designed to house electrical, electronic, hydraulic or pneumatic controls and instruments
- Provides protection where equipment may be hosed down or otherwise be very wet, or in specific applications where corrosion is a serious problem.

### Construction

- Formed 12 gauge 304 or 316 stainless steel.
- Smooth, continuously welded seams without knockouts, cutouts or holes.
- Doors are supported with heavy gauge continuous hinges.
- 3-pt padlocking door handle.
- Seamless poured-in place gasket.
- A grounding stud is provided in the enclosure and a bonding stud is provided on the door.
- Center post is removable for easy installation of the inner panel.

### Standards

- UL 508A Type 3R, 4X, and 12
- CSA Type 3R, 4X, and 12
- Complies with
  - NEMA Type 3R, 4X, 12 and 13
  - IEC 60529, IP66

### Finish

- Cover and enclosure are natural stainless steel with a smooth brushed finish.
- Removable inner panel is finished in white powder coating.

### Accessories

- Door Stop Kit
- Drip Shield Kit
- Mechanical Interlock
- Climate Control
- General Accessories
- Type 12/4, 4X Handle Kits
- Window Kits
- Barrier Kits for Type 4 Wallmount
- Lighting

**New and improved PDF part drawing files with more detail now available.**

Click part number in table below to access PDF, DXF, and STEP files.

| 304 S.S.<br>Part Number | 316 S.S.<br>Part Number | Enclosure |       |       | Panel |       |
|-------------------------|-------------------------|-----------|-------|-------|-------|-------|
|                         |                         | H         | W     | D     | H     | W     |
| HN4WM24428SS            | HN4WM24428S16           | 24.00     | 42.00 | 8.00  | 21.00 | 39.00 |
| HN4WM24488SS            | HN4WM24488S16           | 24.00     | 48.00 | 8.00  | 21.00 | 45.00 |
| HN4WM304210SS           | HN4WM304210S16          | 30.00     | 42.00 | 10.00 | 27.00 | 39.00 |
| HN4WM304810SS           | HN4WM304810S16          | 30.00     | 48.00 | 10.00 | 27.00 | 45.00 |
| HN4WM306010SS           | HN4WM306010S16          | 30.00     | 60.00 | 10.00 | 27.00 | 57.00 |
| HN4WM364212SS           | HN4WM364212S16          | 36.00     | 42.00 | 12.00 | 33.00 | 39.00 |
| HN4WM364812SS           | HN4WM364812S16          | 36.00     | 48.00 | 12.00 | 33.00 | 45.00 |
| HN4WM366012SS           | HN4WM366012S16          | 36.00     | 60.00 | 12.00 | 33.00 | 57.00 |
| HN4WM424212SS           | HN4WM424212S16          | 42.00     | 42.00 | 12.00 | 39.00 | 39.00 |
| HN4WM424812SS           | HN4WM424812S16          | 42.00     | 48.00 | 12.00 | 39.00 | 45.00 |
| HN4WM426012SS           | HN4WM426012S16          | 42.00     | 60.00 | 12.00 | 38.00 | 56.00 |
| HN4WM484812SS           | HN4WM484812S16          | 48.00     | 48.00 | 12.00 | 44.00 | 44.00 |

Tags: **HN4WM, wallmount, two door, stainless steel, 304, 316, outdoor, hydraulic, pneumatic, controls,** *Data subject to change without notice*  
**Type 4X, NEMA 4X**

© 2025. Hammond Manufacturing Ltd. All rights reserved.