



Quality Products. Service Excellence.

Variable Wall Rack *VWR Series*

Load rated to 110 lbs (50 kg)



Note: This product line will be discontinued on October 31, 2025 at which time it will only be available while supplies last. No returns will be possible after the discontinuation date.

The suggested replacement will be **VPB Series**. For alternative solution assistance, please **contact Hammond here** or call: USA (716) 630-7030, Canada and International (519) 822-2960.

Features




- Constructed in 16-gauge steel and 14-gauge steel (rails).
- EIA compliant 19" mounting rails are 10-32 threaded.
- Available in 4U, 6U and 8U sizes.
- Rails mount in three (3) positions to accommodate various equipment mounting.
- Rear cable access with tie points for cable management.
- Opening in the rear is large enough for cable access or wall mounting over an electrical outlet.
- Self-squaring design ships un-assembled (some assembly required).
- Includes a pack of twenty-five (25) **TSCREW1032-25** thumb screws for rack installation.
- 110 lbs (50 kg) **static load rating**.
- Finished in RAL9003 white powder paint. Complies with the Greenguard guidelines for indoor air quality.
- TAA-compliant for federal GSA schedule purchases within the USA.
- RoHS Compliant.
- Manufactured in North America.

Accessories

- Ground Stud Kit



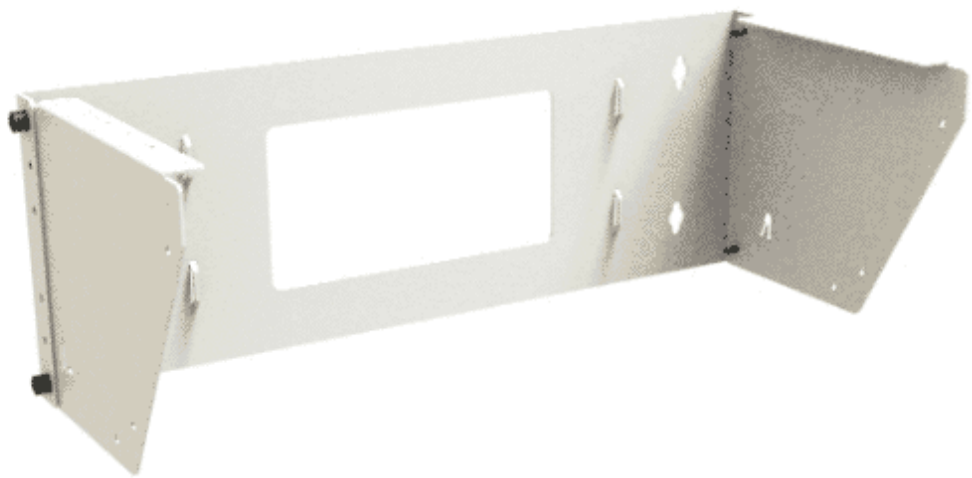

Part No.	Overall Dimensions			Rack Units	Mounting Dimensions	
	Height	Width	Depth		Height	Width
VWR4UWH	7.00	20.37	8.90	4U	7.00	19.00
VWR6UWH	10.50	20.37	12.40	6U	10.50	19.00
VWR8UWH	14.00	20.37	15.90	8U	14.00	19.00

Data subject to change without notice

© 2025. Hammond Manufacturing Ltd. All rights reserved.