


Max. span length

Cable Ring with Reset Only

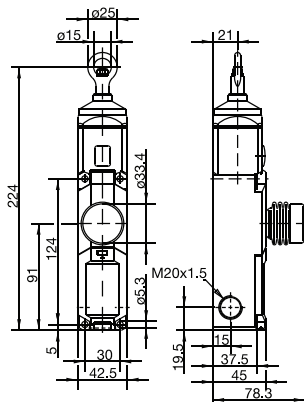

	2 NC/2 NO 601.1621.064 SR-U2Z-0-LU-100-L0-0-0	4 NC 601.1691.074 SR-A4Z-0-LU-100-L0-0-0
82 Ft. (25 Meters)	Replaces 601.1621.030 SR-U2Z 100	Replaces 601.1691.033 SR-A4Z 100
	601.1621.065 SR-U2Z-0-LU-175-L0-0-0	601.1691.075 SR-A4Z-0-LU-175-L0-0-0
123 Ft. (37.5 Meters)	Replaces 601.1621.026 SR-U2Z 175	Replaces 601.1691.047 SR-A4Z 175
	601.1621.066 SR-U2Z-0-LU-300-L0-0-0	601.1691.076 SR-A4Z-0-LU-300-L0-0-0
246 Ft. (75 Meters)	Replaces 601.1620.020 SR-U2Z 300	Replaces 601.1691.048 SR-A4Z 300

Approvals



Contact type	2 NC / 2 NO (Zb)	4 NC
Action contacts	U2Z	A4Z
Circuit symbol		
Switching Diagram		