

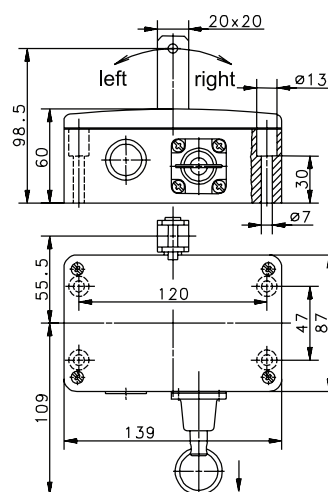



SI1

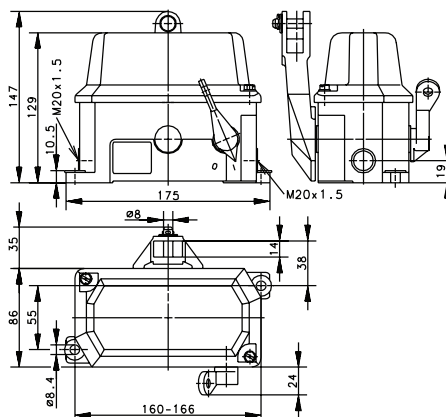

601.5625.001
SIRK-U2Z R
2 x 75 m

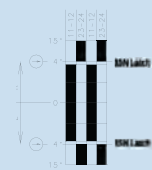


601.4735.001
SI1-U2Z AK R-RAST
2 x 50 m

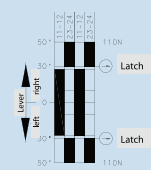

Article No.	Designation	Max. span
-------------	-------------	-----------

 601.4735.025
SI1-U1Z/U1Z AK R-RAST
2 x 50 m



Article No.	Designation	Max. span
-------------	-------------	-----------

Maximum Switching Voltage
Maximum Switching Amperage
B10d
Mechanical Service Life
Switching Frequency
Operating Temperature
Protection Rating
Utilization Category
Rate Insulation Voltage
Approvals

240V
10A
0.2 Million
 1×10^5
 $\leq 30/\text{min}$
 -30°C to $+80^\circ\text{C}$
IP65
AC 15, A 300 240 V / 3 A, 120 V / 6 A
DC 13, Q300 250 V / 0.27 A, 125 V / 0.55 A
250VAC



240V
10A
2 Million
 1×10^5
 $\leq 10/\text{min}$
 -30°C to $+80^\circ\text{C}$
IP65
AC-15, U_i / I_e 240 V / 3 A
250VAC



Drawing dimensions in mm