
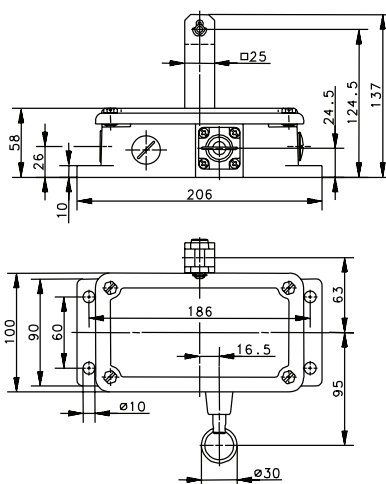


SI2 Series

SIRK

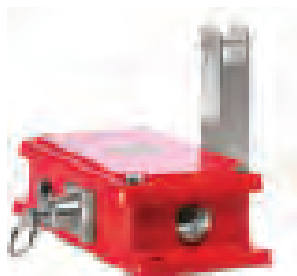

Variant 1

Article No.
Designation
Max. span

601.5735.002
SI2-U2Z AK R-RAST
2 x 50 m

Variant 2

Article No.
Designation
Max. span

Variant 3

Article No.
Designation
Max. span

Technical Information

Maximum Switching Voltage	240V
Maximum Switching Amperage	10A
B10d	2 Million
Mechanical Service Life	1 x 10 ⁶
Switching Frequency	≤ 10/min
Operating Temperature	-30 °C to +80 °C
Protection Rating	IP65
Utilization Category	AC-15, 240 V/3 A
Rate Insulation Voltage	400VAC
Approvals	

