 


Cable Clamps, Cable, Springs, Turnbuckles & Pulleys

4 Cable grip, duplex



Size	LG	BR	H1	H2	Art. No.
2	35 mm	12 mm	5 mm	11 mm	269.0000.010
3	35 mm	14 mm	6 mm	14 mm	269.0000.011
4	40 mm	17 mm	7 mm	16 mm	269.0000.012

Material: Steel strip

Coating: Blue passivated, RoHS-compliant

5 Cable




Cable Ø / Sheath Ø	Design	Minimum breaking strength	Art. No.
D 1,8/D 5	Similar to DIN 3055	275 kp	369.9100.008
D 2 / D 2.5	to DIN 3055	239 kp	369.9100.024
D 3/D 4	to DIN 3055	538 kp	369.9100.025
D 4/D 5	to DIN 3055	957 kp	369.9100.026

Material: Fiber-core galvanized, strength 1770 N/mm²

Coating: Blue passivated, RoHS-compliant


6 Compression spring, eye shape to DIN 1479

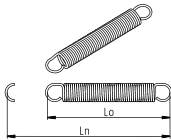

Fo	Fn	R	Lo	Ln	Art. No.
18 N	296 N	1.269 N/mm	188 mm	408 mm	365.2100.331
24 N	354 N	2.466 N/mm	180 mm	314 mm	365.2100.332
13.3 N	153 N	0.694 N/mm	185 mm	387 mm	365.2100.211
35.2 N	450 N	3.490 N/mm	201 mm	319 mm	365.2100.198

Material: Wire to DIN 2076 - 1.4310

 7 Pull cable spring




Fn	R	Lo	Ln	Art. No.
218 N	2.1 N/mm	383 mm	487 mm	391.1042.153
335 N	1.9 N/mm	483 mm	653 mm	391.1042.154

Material: Wire to DIN 2076 - 1.4310, cable grip - zinc pressure die-cast alloy, eye bolt to DIN 444 - 4.6

Coating: Thick-layer passivated (except spring), RoHS-compliant

 7 Turnbuckle sleeve



Size	Art. No.
M 6	2601479188
M 8	2601479189

Material: Steel, min. tensile strength 330 N/mm²

Coating: Blue passivated, RoHS-compliant

7 Turnbuckle similar to DIN 1480 with two eyes




Open	Art. No.
M 5 x 50	260.1480.016
M 6 x 60	260.1480.017

Material: Steel, forged

Coating: Blue passivated, RoHS-compliant

8 Pulley block, swivel version

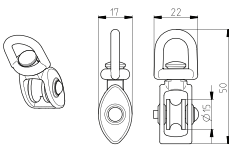


Art. No.
2690000023

Material: Zinc pressure die-cast alloy
(pulley polyamide)

Coating: Blue passivated, RoHS-compliant

8 Pulley block, fixed version

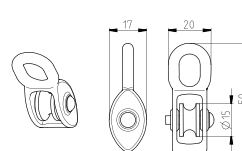

Art. No.
260.0000.022

Material: Zinc pressure die-cast alloy
(pulley polyamide)

Coating: Blue passivated, RoHS-compliant

9 Mounting bracket for pulley to DIN 1142




Art. No.
3911751437

Material: Steel

Coating: Blue passivated, RoHS-compliant

Deflection pulley Ø 75 mm for cable diameter up to 8 mm

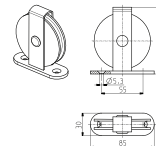

Art. No.
269.0000.051

Material: Steel/polyamide

Coating: Blue passivated, RoHS-compliant