
 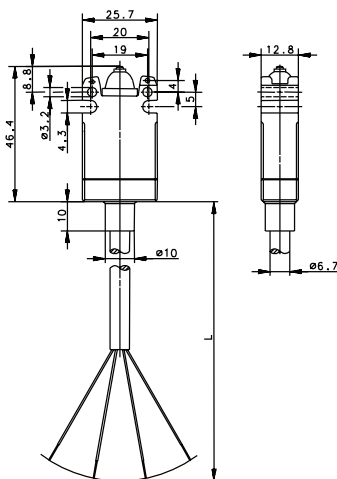


EEX W

609.0153.002
EEX-SU1ZW-2M-

 
[illegible]

609.0148.022
EEX-SU1Z RH -2M-



—


609.0148.024
EEX-SU1Z RH -5M-



609.0153.005
EEX-SU1Z W -9M-



 609.0148.025
EEX-SU1Z RH -9M-



 II 2 G EEx d II CT6

 II 2 G EEx d II CT6

Maximum Switching Voltage
Maximum Switching Amperage
B10d
Mechanical Service Life
Switching Frequency
Operating Temperature
Protection Rating
Utilization Category
Rate Insulation Voltage

230V
5A
4 Million
 2×10^6
 $\leq 120/\text{min}$
 $-20\text{ }^{\circ}\text{C}$ to $+65\text{ }^{\circ}\text{C}$
IP66 / IP67
AC 15, 240 V / 3 A;
DC 13, 250 V / 0.27 A
250VAC

230V
5A
4 Million
 2×10^6
 $\leq 120/\text{min}$
 -20°C to $+65^\circ\text{C}$
IP66 / IP67
AC 15, 240 V / 3 A;
DC 13, 250 V / 0.27 A
250VAC