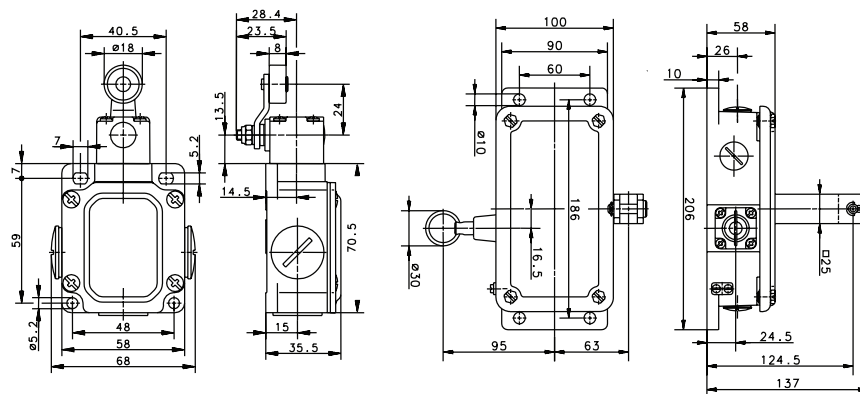


 
SN2 Series Limit Switch and Double Sided Cable Pull Switch

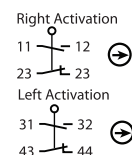
SN2 Limit Switch without Cable

Series SI2 Double Sided Rope Pull



1 NC / 1 NO contact

619.3285.001
 SN2-SU1Z AH EXD 180 Gr.

-
-

609.1288.024
 SI2-U2Z AK EXD


2 NC / 2 NO contacts

-
-

-
-

EX Certification

Ex II 2 D IP65 T 85 °C

Ex II 3 D Ex tD A22 IP65 T 80°C

Technical Information

Maximum Switching Voltage
 Maximum Switching Amperage
 B10d
 Mechanical Service Life
 Switching Frequency
 Operating Temperature
 Protection Rating
 Utilization Category
 Rate Insulation Voltage

240V
 10A
 20 Million
 10 x 10⁶
 ≤ 60/min
 -20 °C to +80 °C
 IP65
 AC 15, 240 V / 3 A;
 DC 13, 250 V / 0.27 A
 400VAC

240V
 10A
 4 Million
 2 x 10⁶
 ≤ 10/min
 -20 °C to +80 °C
 IP65
 AC 15, 240 V / 3 A;
 DC 13, 250 V / 0.27 A
 400VAC