



GC Series

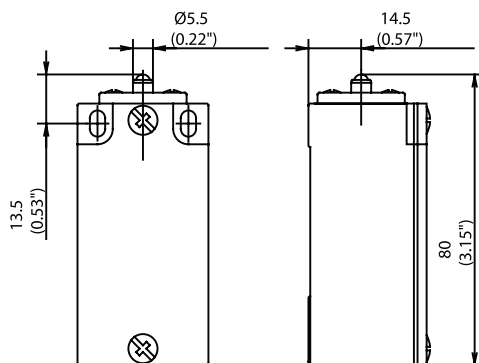

IW



STIW

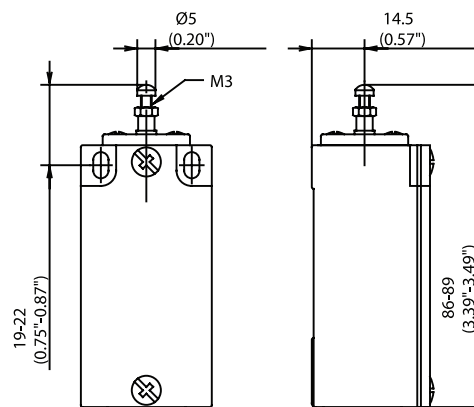


Switching Operation

1 NC / 1 NO Contacts


Slow Action

 602.1102.001
GC-U1Z IW




Snap Action

 602.1352.620
GC-SU1Z IW




Slow Action

 602.1105.015
GC-U1Z STIW




Snap Action

 602.1155.017
GC-SU1Z STIW



2 NC Contacts

 602.1802.189
GC-A2Z IW



-

-

-

2 NO Contacts

-

-

-

 
-

1 NC / 1 NO Contacts Overlapping

-

-

602.1305.016
GC-UV1Z STIW



-

Replacement actuator:

391.2030.546

391.2050.523

Technical Information

Slow Action

Snap Action

Maximum Switching Voltage

240V

240V

Max. Switching Amps (up to)*

10A

10A

B10d (up to)*

20 Million

20 Million

Mechanical Service Life (up to)*

10 x 10⁶

10 x 10⁶

Switching Frequency

≤ 100/min

≤ 100/min

Operating Temperature

-30 °C to +80 °C

-30 °C to +80 °C

Protection Rating

IP65

IP65

Utilization Category (up to)*

AC-15, Ue/Ue 240V 3A

AC-15, Ue/Ue 240V 3A

Rate Insulation Voltage

400VAC

400VAC

Approvals

* Depending on switching system - see technical information for details



Special features/variants (on request)

Special features/variants (on request)

- Actuator length adjustable with adjusting screw

Drawing dimensions in mm