



GC Series



AV

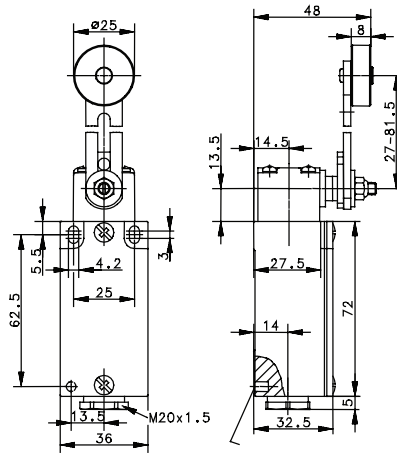

AD

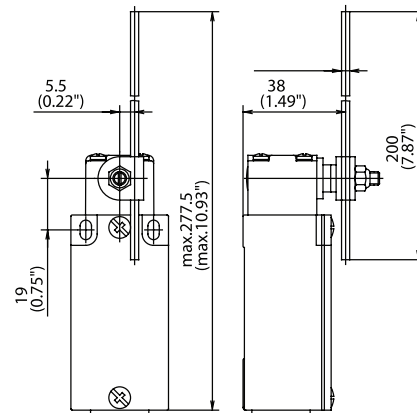


Switching Operation

1 NC / 1 NO Contacts


Slow Action

 602.1136.104
GC-U1 AV




Snap Action

 602.1186.118
GC-SU1 AV




Slow Action

 602.1137.103
GC-U1 AD



Snap Action

 602.1187.125
GC-SU1 AD



2 NC Contacts

-

-

-

-

2 NO Contacts

-

-

-

-

**1 NC / 1 NO Contacts
Overlapping**

-

-

-

-

Replacement actuator:

391.2360.723

391.2370.724

Technical Information

Slow Action

Snap Action

Maximum Switching Voltage	240V	240V
Max. Switching Amps (up to)*	10A	10A
B10d (up to)*	20 Million	20 Million
Mechanical Service Life (up to)*	10 x 10 ⁶	10 x 10 ⁶
Switching Frequency	≤ 100/min	≤ 100/min
Operating Temperature	-30 °C to +80 °C	-30 °C to +80 °C
Protection Rating	IP65	IP65
Utilization Category (up to)*	AC-15, Ue/Ue 240V 3A	AC-15, Ue/Ue 240V 3A
Rate Insulation Voltage	400VAC	400VAC
Approvals	* Depending on switching system - see technical information for details	



Special features/variants (on request)

- Different roller diameters and lever lengths
- With roller over switch and with 2 NC / 2 NO contact

Special features/variants (on request)

- Available different actuator lengths and actuator directions
- With 2 NC / 1 NO with overlap contacts (larger enclosure)

Drawing dimensions in mm