



SN2 Series

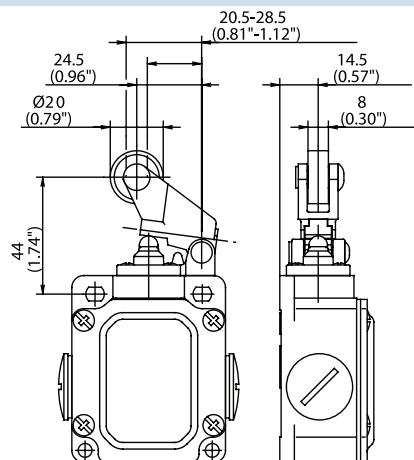

DGHW



DGKW

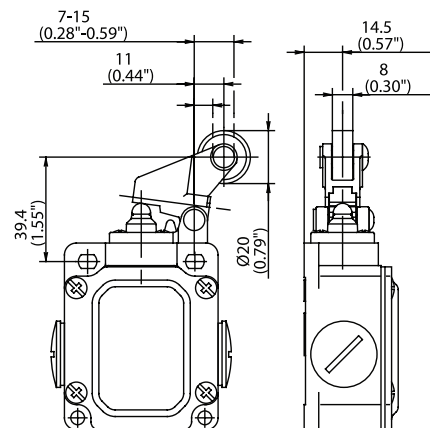


Switching Operation

1 NC / 1 NO Contacts


Slow Action

 603.3121.005
SN2-U1Z DGHW




Snap Action

 603.3371.004
SN2-SU1Z DGHW




Slow Action

 603.3127.010
SN2-U1Z DGKW



Snap Action

 603.3377.011
SN2-SU1Z DGKW



2 NC Contacts

-

-

-

-

2 NO Contacts

-

-

-

-

1 NC / 1 NO Contacts Overlapping

-

-

-

-

Replacement actuator:

391.8211.656

391.8271.655

Technical Information

Slow Action

Snap Action

Maximum Switching Voltage

240V

240V

Max. Switching Amps (up to)*

10A

10A

B10d (up to)*

20 Million

20 Million

Mechanical Service Life (up to)*

10 x 10⁶

10 x 10⁶

Switching Frequency

≤ 100/min

≤ 100/min

Operating Temperature

-30 °C to +80 °C

-30 °C to +80 °C

Protection Rating

IP65

IP65

Utilization Category (up to)*

AC-15, Ue/Ue 240V 3A

AC-15, Ue/Ue 240V 3A

Rate Insulation Voltage

400VAC

400VAC

Approvals

* Depending on switching system - see technical information for details



Special features/variants (on request)

- Telescopic plunger, very long actuation travel of 9 mm

Drawing dimensions in mm