



ENM2 Series



AHS-V (Form A)

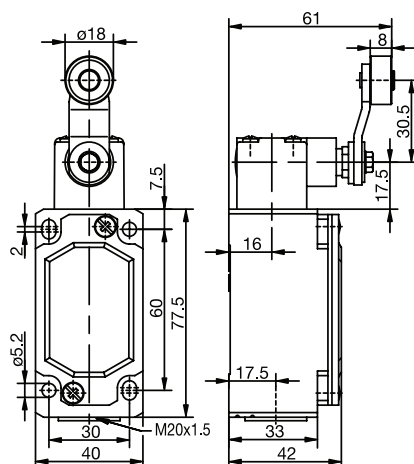

DGHW RO20

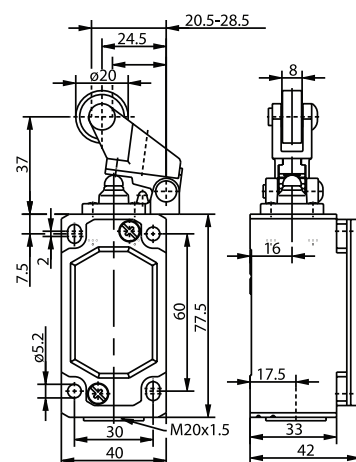


Switching Operation

1 NC / 1 NO Contacts


Slow Action

 608.7135.013
ENM2-U1Z AHS-V




Snap Action

 608.7385.014
ENM2-SU1Z AHS-V




Slow Action

 608.7121.007
ENM2-U1Z DGHW RO20




Snap Action

 608.7371.008
ENM2-SU1Z DGHW RO20




2 NC Contacts

 608.7835.015
ENM2-A2Z AHS-V



-
-

 608.7821.009
ENM2-A2Z DGHW RO20



-
-

2 NO Contacts

-
-

-
-

-
-

-
-

1 NC / 1 NO Contacts Overlapping

-
-

-
-

-
-

-
-

Replacement actuator:

391.8350.729

391.8211.656

Technical Information

Slow Action

Snap Action

Maximum Switching Voltage

240V

240V

Max. Switching Amps (up to)*

10A

10A

B10d (up to)*

20 Million

20 Million

Mechanical Service Life (up to)*

3 x 10⁶

10 x 10⁶

Switching Frequency

≤ 100/min

≤ 100/min

Operating Temperature

-30 °C to +80 °C

-30 °C to +80 °C

Protection Rating

IP65

IP65

Utilization Category (up to)*

AC-15, Ue/Ue 240V 3A

AC-15, Ue/Ue 240V 3A

Rate Insulation Voltage

400VAC

400VAC

Approvals

* Depending on switching system - see technical information for details



Special features/variants (on request)

- Available with different directions

Special features/variants (on request)

- Available with different directions

Drawing dimensions in mm