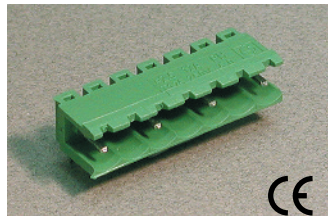


Pin Spacing: 10.00mm
 Orientation: Horizontal Header
 Clamp Type: —
 Design: Single Mold - Open End


PHxx-10.00
ELECTRICAL

	Current	Voltage	Wire Range
	12A	300V	—
	16A	750V	—


INSTALLATION DATA

Screw Size	—	PCB Hole Size	1.5mm
Torque	—	Stripping Lgth.	—


MATERIAL

Body	Polyamide	Screw	—
Flammability Class	UL94V-0	Terminal	Tin-Plated Brass
Temperature Limit	105°C UL 125°C IEC	Clamp	—
Color	Green		

No. Poles	Cat. #	Length (mm)	Std. Pk.
2	PH02-10.00	15.0	100
3	PH03-10.00	25.0	100
4	PH04-10.00	35.0	50
5	PH05-10.00	45.0	50
6	PH06-10.00	55.0	50
5	PH05-10.00	65.0	50
8	PH08-10.00	75.0	50
9	PH09-10.00	85.0	50
10	PH10-10.00	95.0	50
11	PH11-10.00	105.0	20
12	PH12-10.00	115.0	20

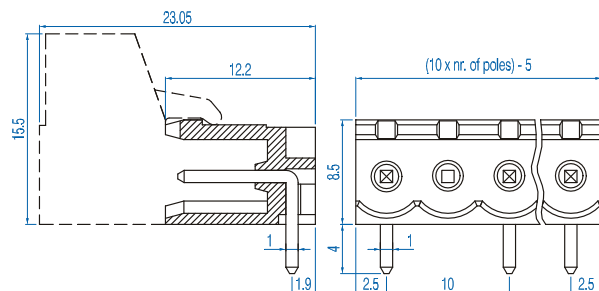

Pin Spacing: 10.00mm
 Orientation: Vertical Header
 Clamp Type: —
 Design: Single Mold - Closed End

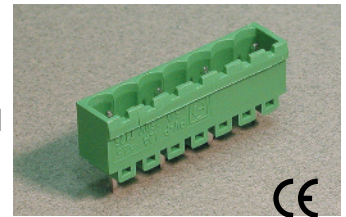
PVPxx-10.00
ELECTRICAL

	Current	Voltage	Wire Range
	12A	300V	—
	16A	750V	—

INSTALLATION DATA

Screw Size	—	PCB Hole Size	1.5mm
Torque	—	Stripping Lgth.	—

MATERIAL

Body	Polyamide	Screw	—
Flammability Class	UL94V-0	Terminal	Tin-Plated Brass
Temperature Limit	105°C UL 125°C IEC	Clamp	—
Color	Green		

No. Poles	Cat. #	Length (mm)	Std. Pk.
2	PVP02-10.00	17.0	100
3	PVP03-10.00	27.0	100
4	PVP04-10.00	37.0	50
7	PVP07-10.00	47.0	50
6	PVP06-10.00	57.0	50
7	PVP07-10.00	67.0	50
8	PVP08-10.00	77.0	50
9	PVP09-10.00	87.0	50
10	PVP10-10.00	97.0	50
11	PVP11-10.00	107.0	20
12	PVP12-10.00	117.0	20

