


# 10.16mm Pin Spacing – Pluggable PCB Blocks

Pin Spacing: 10.16mm  
 Orientation: Vertical-Double  
 Level Header  
 Clamp Type: –  
 Design: Modular - Open End

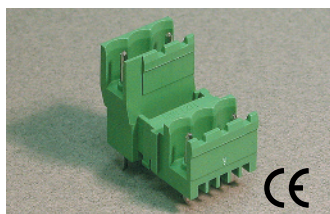

**PDSVxx-10.16**

## ELECTRICAL

|                                                                                   | Current | Voltage | Wire Range |
|-----------------------------------------------------------------------------------|---------|---------|------------|
|  | 12A     | 600V    | –          |
|  | 16A     | 750V    | –          |


## INSTALLATION DATA

|            |   |                 |       |
|------------|---|-----------------|-------|
| Screw Size | – | PCB Hole Size   | 1.5mm |
| Torque     | – | Stripping Lgth. | –     |


## MATERIAL

|                    |                       |          |                  |
|--------------------|-----------------------|----------|------------------|
| Body               | Polyamide             | Screw    | –                |
| Flammability Class | UL94V-0               | Terminal | Tin-Plated Brass |
| Temperature Limit  | 105°C UL<br>125°C IEC | Clamp    | –                |
| Color              | Green                 |          |                  |

| No. Poles | Cat. #       | Length (mm) | Std. Pk. |
|-----------|--------------|-------------|----------|
| 4         | PDSV02-10.16 | 17.8        | 100      |
| 6         | PDSV03-10.16 | 30.5        | 50       |
| 8         | PDSV04-10.16 | 43.2        | 50       |
| 10        | PDSV05-10.16 | 55.9        | 50       |
| 12        | PDSV06-10.16 | 68.6        | 20       |
| 14        | PDSV07-10.16 | 81.3        | 20       |
| 16        | PDSV08-10.16 | 94.0        | 20       |
| 18        | PDSV09-10.16 | 106.7       | 20       |
| 20        | PDSV10-10.16 | 119.4       | 10       |
| 22        | PDSV11-10.16 | 132.1       | 10       |
| 24        | PDSV12-10.16 | 144.8       | 10       |

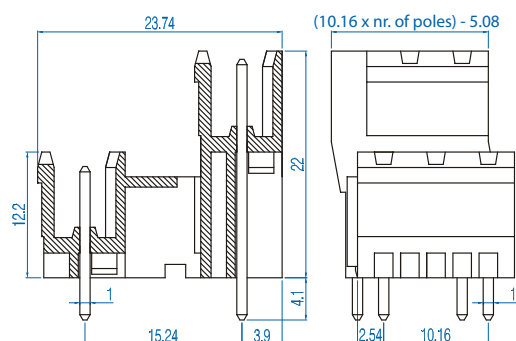

Pin Spacing: 10.16mm  
 Orientation: Horizontal-Double  
 Level Header  
 Clamp Type: –  
 Design: Modular - Open End

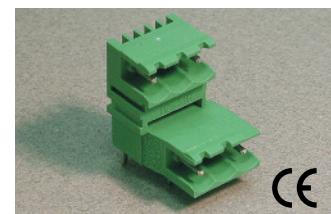

**PDSHxx-10.16**

## ELECTRICAL

|                                                                                   | Current | Voltage | Wire Range |
|-----------------------------------------------------------------------------------|---------|---------|------------|
|  | 12A     | 600V    | –          |
|  | 16A     | 750V    | –          |

## INSTALLATION DATA

|            |   |                 |       |
|------------|---|-----------------|-------|
| Screw Size | – | PCB Hole Size   | 1.5mm |
| Torque     | – | Stripping Lgth. | –     |

## MATERIAL

|                    |                       |          |                  |
|--------------------|-----------------------|----------|------------------|
| Body               | Polyamide             | Screw    | –                |
| Flammability Class | UL94V-0               | Terminal | Tin-Plated Brass |
| Temperature Limit  | 105°C UL<br>125°C IEC | Clamp    | –                |
| Color              | Green                 |          |                  |

| No. Poles | Cat. #       | Length (mm) | Std. Pk. |
|-----------|--------------|-------------|----------|
| 4         | PDSH02-10.16 | 17.8        | 100      |
| 6         | PDSH03-10.16 | 30.5        | 50       |
| 8         | PDSH04-10.16 | 43.2        | 50       |
| 10        | PDSH05-10.16 | 55.9        | 50       |
| 12        | PDSH06-10.16 | 68.6        | 20       |
| 14        | PDSH07-10.16 | 81.3        | 20       |
| 16        | PDSH08-10.16 | 94.0        | 20       |
| 18        | PDSH09-10.16 | 106.7       | 20       |
| 20        | PDSH10-10.16 | 119.4       | 10       |
| 22        | PDSH11-10.16 | 132.1       | 10       |
| 24        | PDSH12-10.16 | 144.8       | 10       |

