


THESE DRAWINGS ARE THE PROPERTY OF QUALTEK ELECTRONICS AND NOT TO BE REPRODUCED FOR OR COMMUNICATED TO A THIRD PARTY WITHOUT THE EXPRESS WRITTEN PERMISSION OF AN OFFICER OF QUALTEK ELECTRONICS.

| REVISION |             |      |          |
|----------|-------------|------|----------|
| REV.     | DESCRIPTION | DATE | APPROVED |
|          |             |      |          |
|          |             |      |          |
|          |             |      |          |

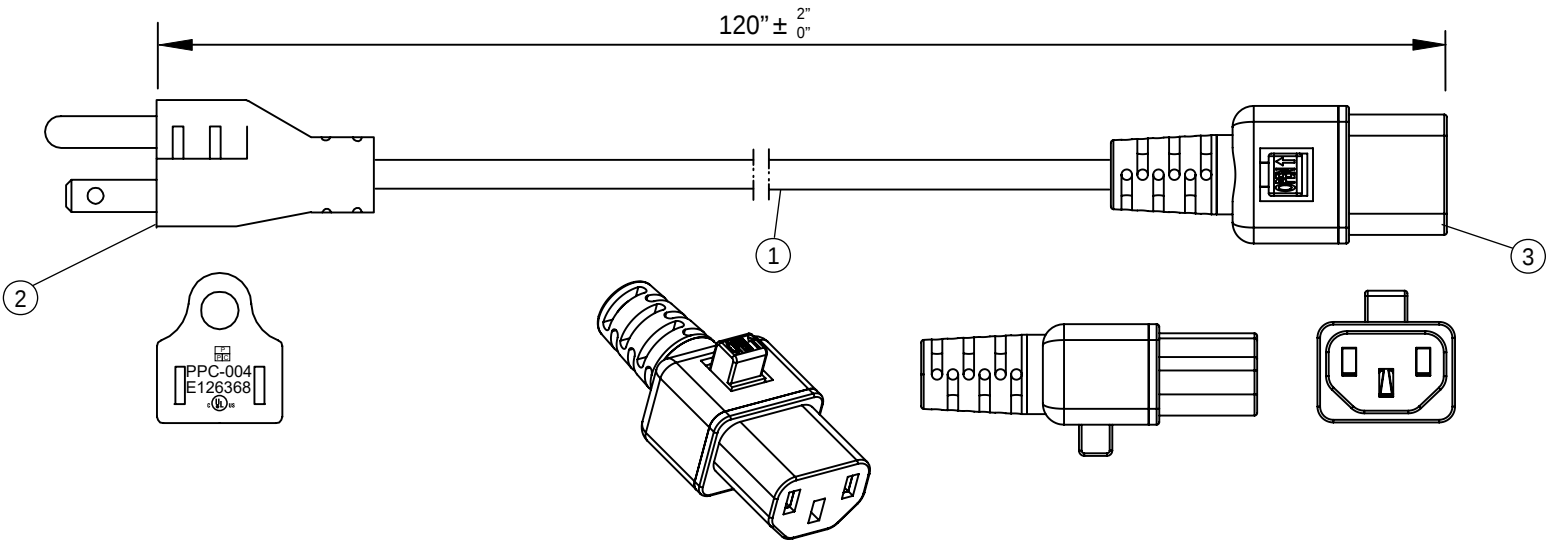

**CONTROLLED**

NOTES:

- 1. CORDAGE: SJTW, 16AWG / 3C, UNSHIELDED, NA COLOR CODE, TEMP. RATING: 105°C, RATING: 125V 13A, JACKET COLOR: BLACK
- 2. PLUG: NEMA 5-15P
- 3. CONNECTOR: LOCKING IEC 60320 C13
- 4. APPROVALS: UL, cUL
- 5. ROHS COMPLIANT
- 6. LOCKING CONNECTOR RATED UP TO MAXIMUM 35LBS.

| Dim range (mm) | Tolerance +/- (mm) | Qualtek Electronics Corp.<br>PPC DIVISION |                |                           |
|----------------|--------------------|-------------------------------------------|----------------|---------------------------|
|                |                    | Part Number:                              | 512009-01      | <div>RoHS Compliant</div> |
| 0-1            | 0.15               | Description:<br>LOCKING POWER CORD        |                |                           |
| 1-6            | 0.20               |                                           |                |                           |
| 6-18           | 0.30               | UNIT: in                                  | UNIT: in       | UNIT: in                  |
| 18-50          | 0.50               |                                           |                |                           |
| 50-120         | 0.70               | Drawn / Date                              | Checked / Date | Approved / Date           |
| 120-250        | 0.90               | R. Nuti<br>03-28-23                       | 03-28-23       | LY / 03-28-23             |
| 250-500        | 1.20               |                                           |                |                           |