

ODU SPRINGTAC socket 1.5 Ag solder-/screw termination M2.6



Basic information

Part number	170.106.100.201.000
Category	Contact

Contact insert description

Contact type	Sockets
Contact diameter	1.5 mm
Termination type	Solder cup
Wire cross section mm²	1.5 mm²

Technical information

Max. current single contact	27 A
Max. current	43 A
Impulse current	1.5 kA
Contact resistance	450 µΩ


Mechanical and environmental data

Total mating force (average) in N/module	5 N
Extraction force	3 N
Weight	1.612 g

Material and surface treatments

Material	Cu-alloy
Contact material	Silver

Graphics and technical drawings

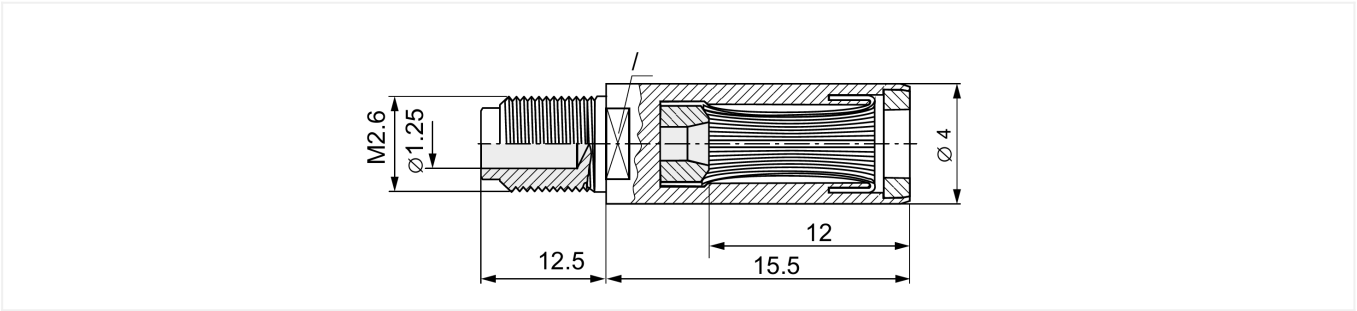

Further technical information and downloads

[3D-File \(STP File\)](#)