

ODU SPRINGTAC Buchse 3,0mm Ag Löt-/Schraubanschluss M4



Basic information

Part number	170.110.100.201.000
Category	Contact

Contact insert description

Contact type	Sockets
Contact diameter	3 mm
Termination type	Screw-solder
Wire cross section mm²	2.3 mm²

Technical information

Max. current single contact	49 A
Max. current	76 A
Impulse current	4 kA
Contact resistance	250 µΩ


Mechanical and environmental data

Total mating force (average) in N/module	10 N
Extraction force	7 N
Weight	6.6 g

Material and surface treatments

Material	Cu-alloy
Contact material	Silver

Graphics and technical drawings

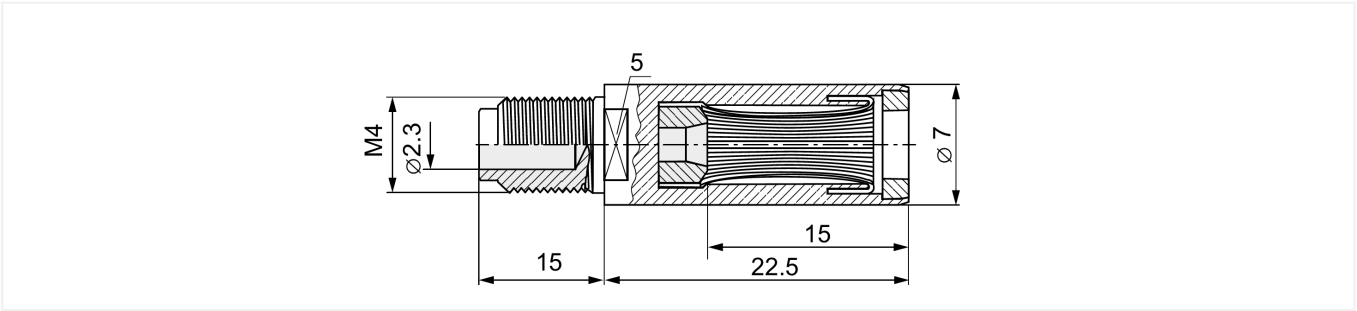

Further technical information and downloads

[3D-File \(STP File\)](#)