

ODU LAMTAC socket 10.0 Ag solder-/screw termination M10



Basic information

Part number	178.117.100.201.000
Category	Contact

Contact insert description

Contact type	Sockets
Contact diameter	10 mm
Termination type	Screw-solder
Wire cross section mm²	35 mm²

Technical information

Max. current single contact	190 A
Max. current	340 A
Impulse current	27 kA
Contact resistance	70 µΩ


Mechanical and environmental data

Total mating force (average) in N/module	30 N
Extraction force	25 N
Weight	50.78 g

Material and surface treatments

Material	Cu-alloy
Contact material	Silver

Graphics and technical drawings

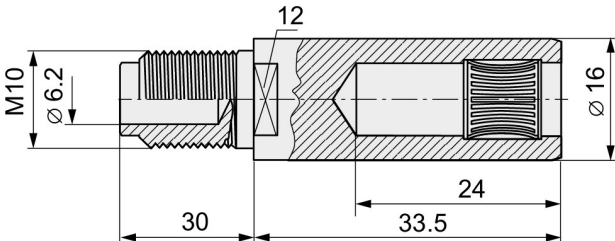

Further technical information and downloads

[3D-File \(STP File\)](#)