




Protecting cover for spindle locking, type B, with rope and center module
IP40, size 4

General information

Part number	493.097.613.644.001
Size	4
Weight	140,0 g
customs tariff numbers	83099090



Illustrations may differ from original product.
Dimensions, unless otherwise specified, in mm.

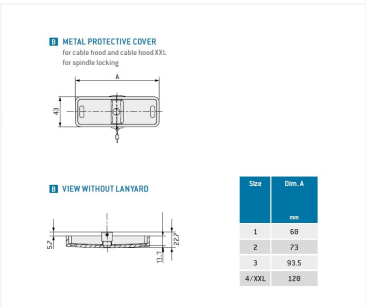

Mechanical and environmental data

Degree of protection*	IP40
Operating temperature	-40 °C – 125 °C

Material and surface treatments

Housing	Aluminum die casting (body)
---------	-----------------------------

ODU reserves the right to make changes based on the current state of knowledge without prior notice without being obliged to provide replacement deliveries or refinements of older designs.