

656.564.001.000.000

ODU-MAC® Blue-Line



PUSH-LOCK receptacle housing, without contacts

Receptacle for integration in your device



Basic information

Part number	656.564.001.000.000
Category	Receptacle
Number of units	7

Cable description

Cable outlet position	Top
-----------------------	-----

Mechanical and environmental data



Locking principle	Push-Pull
Mating cycles	5000
IP class	IP67
Max. operating temperature	125 °C
Min. operating temperature	-40 °C
Weight	84.83 g

Material and surface treatments

Material	Lexan PC
----------	----------

ODU reserves the right to make changes based on the current state of knowledge without prior notice without being obliged to provide replacement deliveries or refinements of older designs.

Graphics and technical drawings

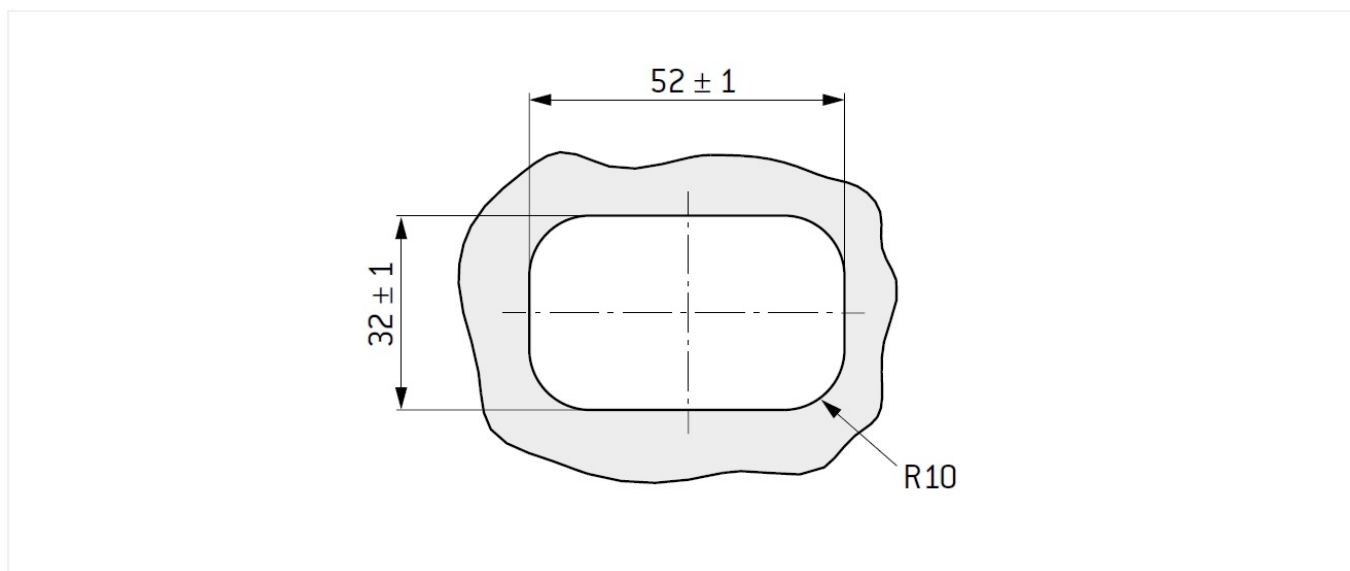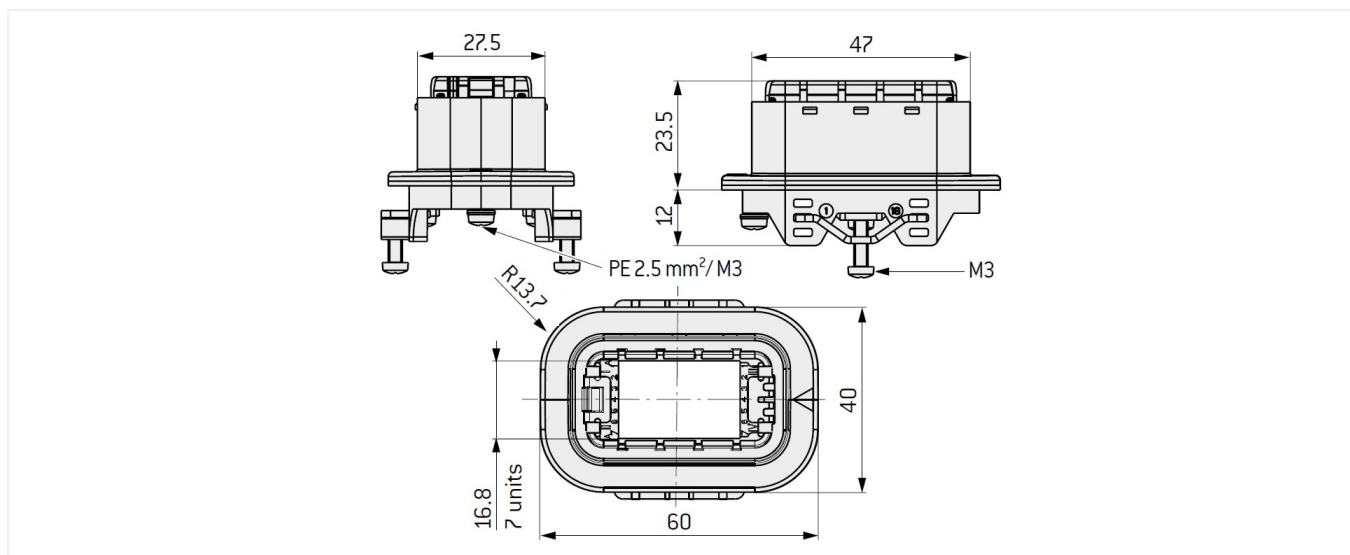

Further technical information and downloads

[3D-File \(STP File\)](#)

[Assembly Instruction](#)