



Panel Cutout

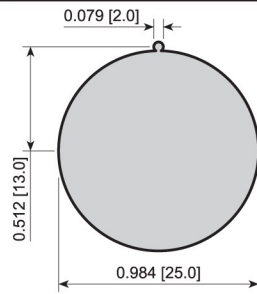


Water Protection Option

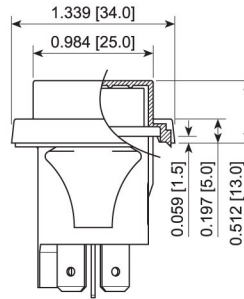

PVC Cap (IP54)

Illumination Option

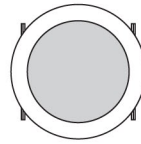

Full

FEATURES

- High Rating with UL
- Maintained and Momentary Option
- PVC Cap for Water and Dust Protection

SPECIFICATIONS:

RATING: RATING OPTION C:

16A 125VAC [UL, cUL]

3/4HP 250VAC [UL, cUL]

TEMPERATURE: -20°C to 105°C [UL, cUL]

ELECTRICAL LIFE: 10,000 Cycles

CONTACT RESISTANCE: 35mΩ Max.

INSULATION RESISTANCE: 100MΩ Min. at 500VDC

DIELECTRIC STRENGTH: 1,500VAC for 1 Minute

INGRESS PROTECTION: IP54 with PVC Cap

MATERIALS:



BODY: Polyamide 6/6, UL94 V-2

ACTUATOR: Polyamide 6/6, UL94 V-2

Polycarbonate, UL94 V-2

CONTACTS: Silver Alloy

TERMINALS: Silver Plated Brass

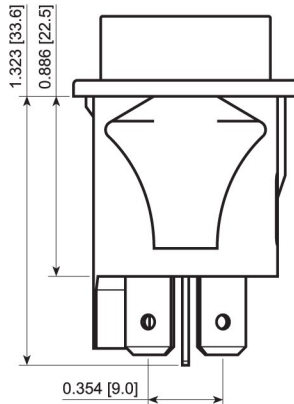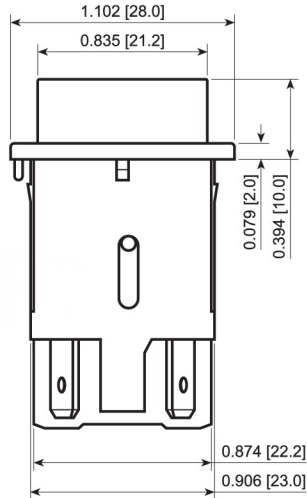

PR142C1000-116



PR144C1200




PR141C1100

PR141C1000-116
ACC-F03-1

Series	Terminal	Function	Rating	Body Color	Actuator Color	Marking Color	Marking Type	Lens Style	Lens Color	Lamp Voltage
PR1	4 - 6.3mm Tabs	1 Pole: 1 - Off-On 4 - Off-(On)	C - 16A 125VAC	1 - Black 2 - White 3 - Almond 4 - Grey 9 - Red	0 - Full Illum. 1 - Black 2 - White 3 - Almond 4 - Grey 5 - Orange 7 - Blue 8 - Green 9 - Red	0 - None 1 - Black 2 - White 8 - Red	0 - None 1 - Power Symbol Vert. 3 - Reset Symbol Vert. 5 - POWER Vert. 7 - RESET Vert.	1 - Full	0 - Clear 1 - Red 2 - Amber 3 - Green 4 - Blue	3 - 6V 4 - 12V 5 - 24V 6 - 125V 7 - 250V
		2 Pole: 2 - Off-On E - Off-(On)								

 Accessories Series Type Options



ACC

PVC Cap and Frame:
F03Colors for Frame:
1 - Black
2 - White

Custom Colors and Markings Available Upon Request

For Illuminated Switches Only

EXAMPLE PART NUMBERS:

PR141C1100 1P Off-On
Black Body/Actuator, No MarkingPR141C1900 1P Off-On
Black Body, Red Actuator, No MarkingPR144C1900 1P Off-(On)
Black Body, Red Actuator, No Marking

E-SWITCH®

www.e-switch.com

800.867.2717