


SERPAC P24

Electronic Enclosures

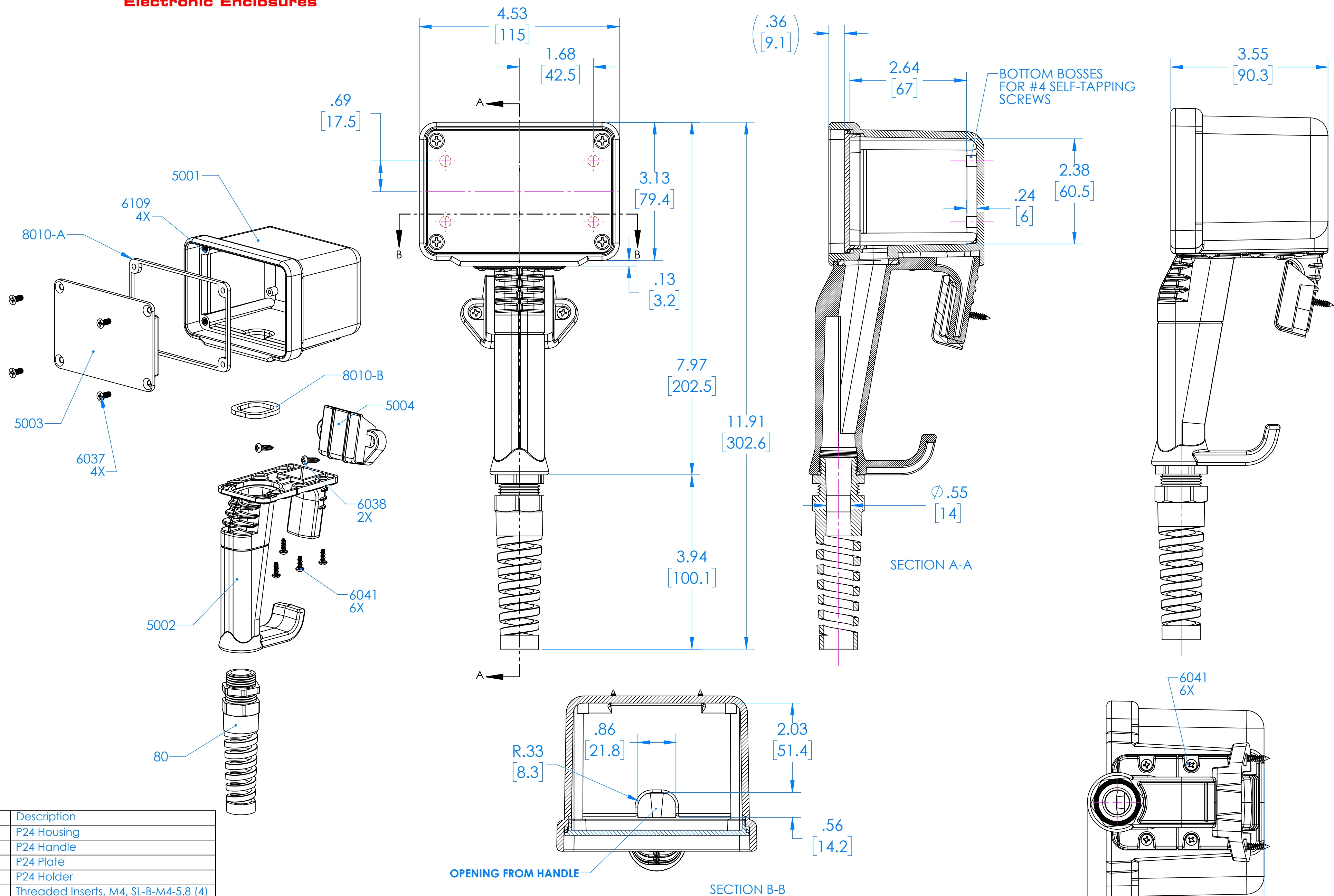

PN	Description
5001	P24 Housing
5002	P24 Handle
5003	P24 Plate
5004	P24 Holder
6109	Threaded Inserts, M4, SL-B-M4-5.8 (4)
80	PG-16 Pigtail
6041	SS Truss Hd, Hi-Lo Screw, #4 x 3/8 (6)
6037	SS Flat Hd. Screw M4 x 10mm (4)
6038	SS Pan Hd Slotted head #6 X 5/8"(2X)
8010-A	P24 Plate Gasket
8010-B	P24 Handle Gasket



Notes:
1. Unit is shipped with Handle/Housing gasket installed.
Plate to Housing gasket is user installed.
2. Dim's in Inch/[mm].
3. Standard Material is UL94 HB Polyester (Yellow or Black).
4. Watertight enclosure meets or exceeds Nema 4x / IP66.

ALL DIMENSIONS ARE $\pm .010"$
2009 Wright Street, La Verne, Ca. 91750
Ph. (626) 331-0517 Fx. (626) 331-8584 serpac.com
3/24/2025


SERPAC Plate & Circuit Board for P24 and P26

Electronic Enclosures

PN 5003 P24 PLATE (INCLUDED)

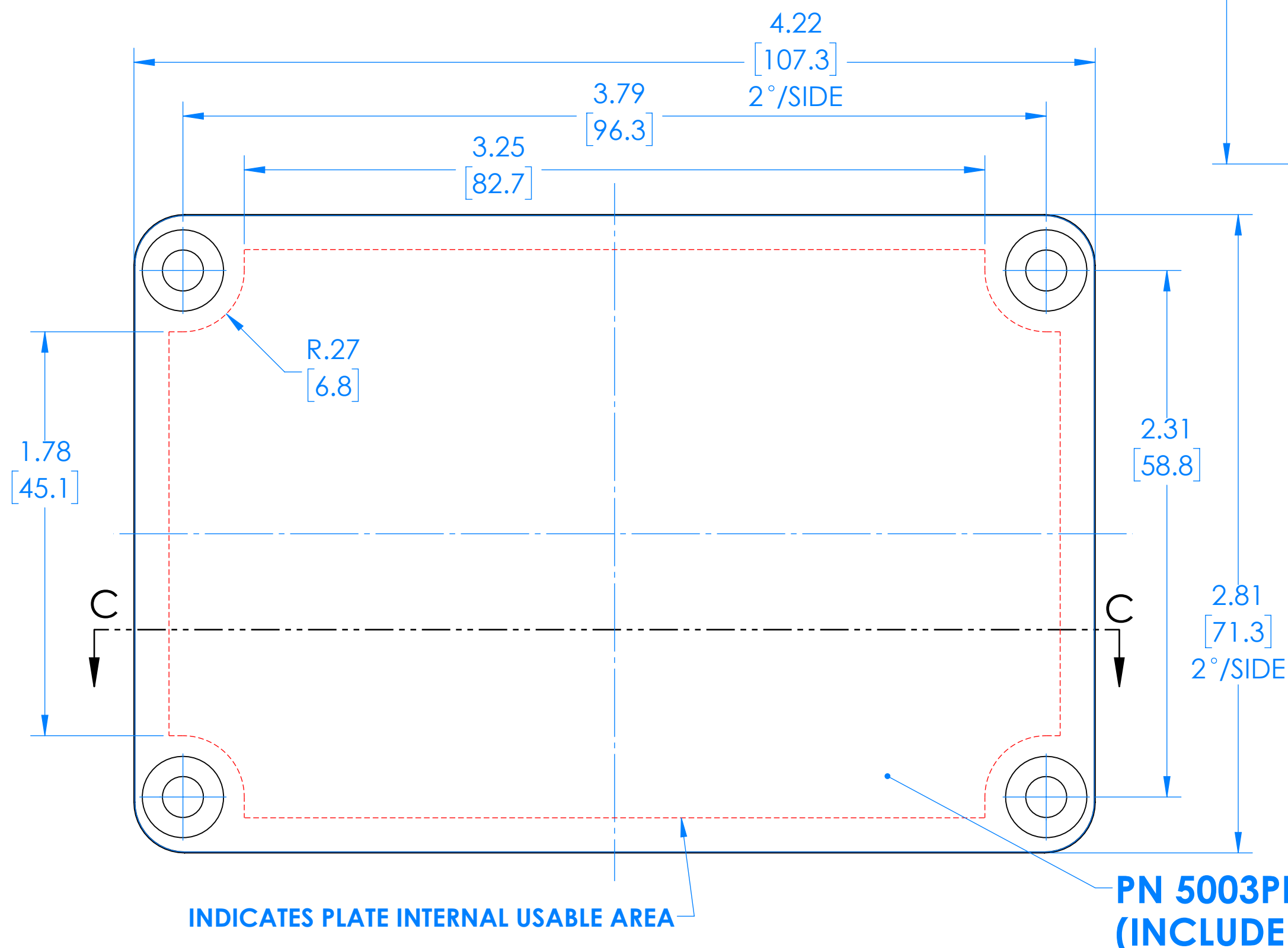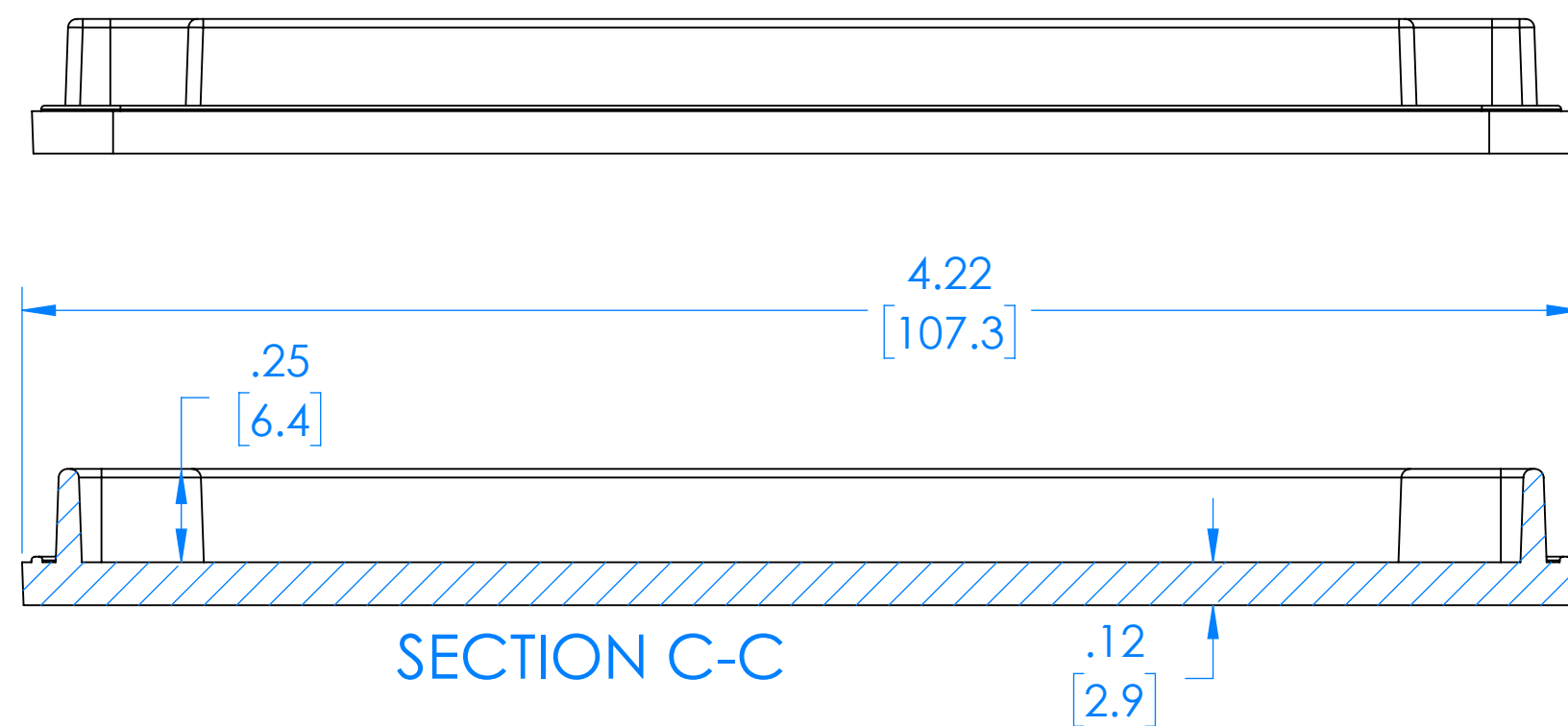

P24-P26 CIRCUIT BOARD (NOT INCLUDED)

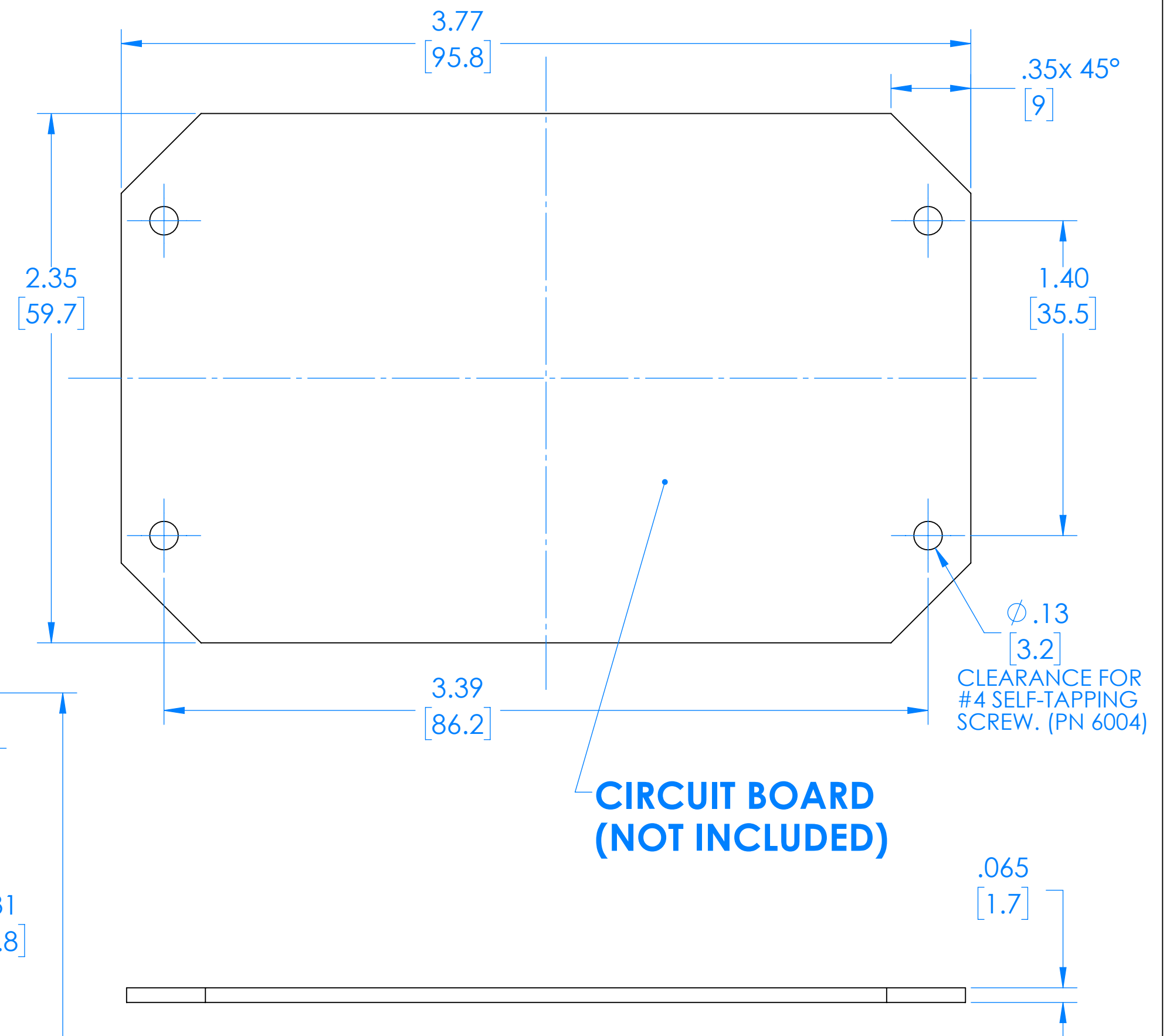

THERE IS A 0.030" ±.005" CLEARANCE FROM THE PERIMETER OF THE CIRCUIT BOARD TO THE INTERIOR OF THE ENCLOSURE.