


MATERIAL SPECIFICATIONS:
GROMMETS: NON-CONDUCTIVE BLACK PVC
OPERATING TEMPERATURE: -40°C to 120°C

	OUTSIDE DIAMETER	MAX. CABLE DIAMETER			
PART NUMBERS	A	B	C	D	E
162-000-925R000	0.400	0.185	0.248	0.290	0.324
162-000-037R000	0.620	0.300	0.400	0.490	
162-000-050R000	0.720	0.320	0.410	0.490	0.650

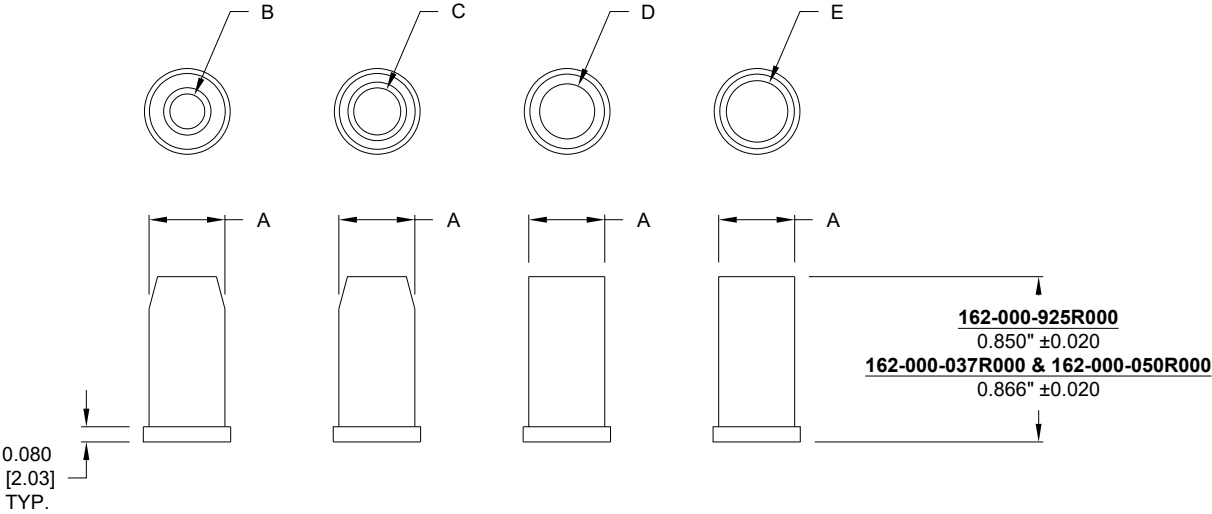

Only (3x) grommets included with part number 162-000-037R000.

Not designed to work with NorComp 981 Series // Please test within your application to ensure form, fit, and function if using with NorComp 981 Series.

RoHS COMPLIANT

DRAWN:
P. JENKINS
DATE:
03/12/2005

UNITS = inch [mm] DO NOT SCALE FROM DRAWING



THESE DRAWINGS AND SPECIFICATIONS ARE THE PROPERTY OF NorComp AND SHALL NOT BE REPRODUCED, COPIED OR USED AS THE BASIS FOR THE MANUFACTURE OR SALE OF APPARATUS WITHOUT WRITTEN PERMISSION.

NorComp

SCALE: NTS
SHEET 1 OF 1
REV 8
DWG NO. 162-000-YYYYR000