




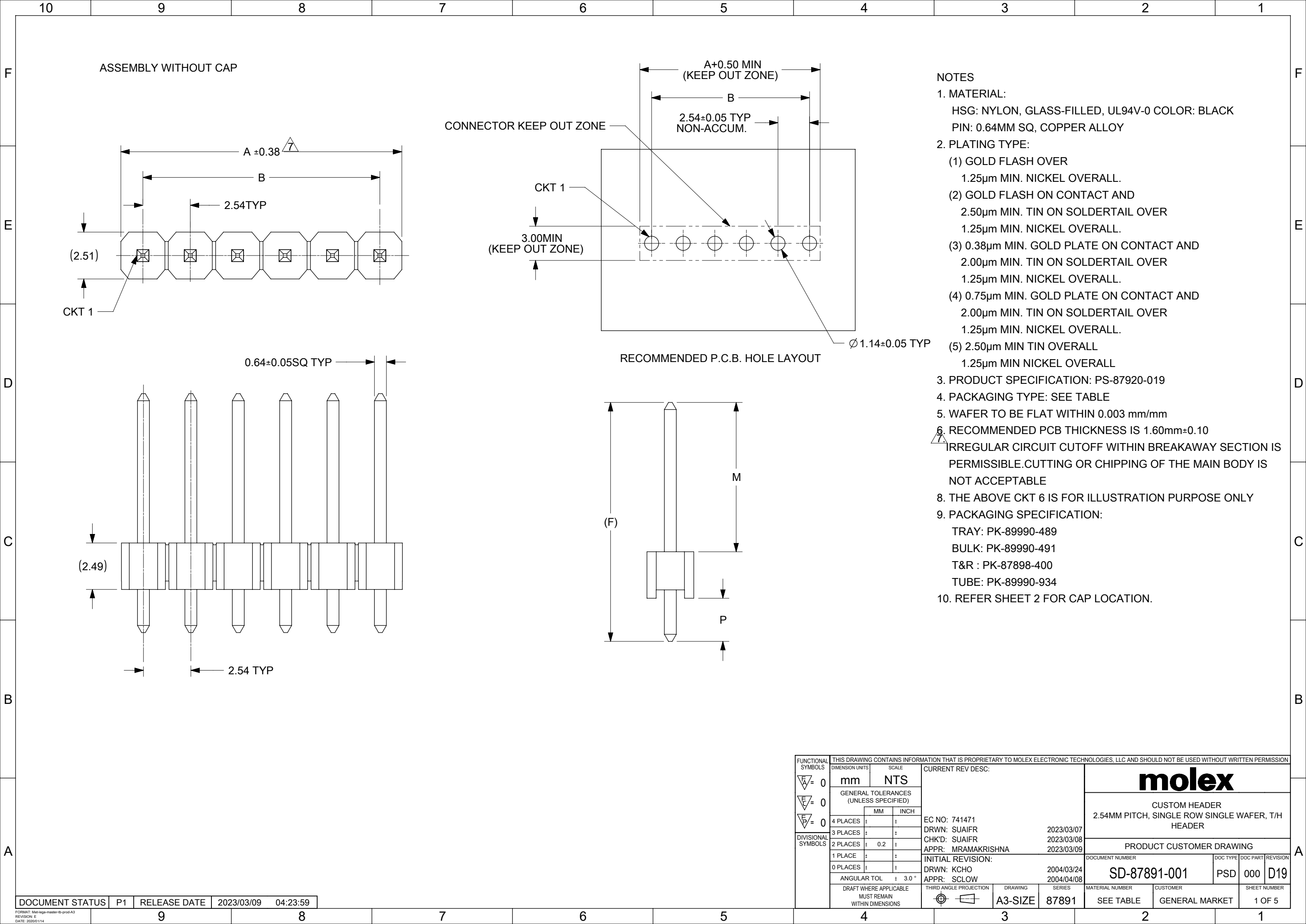


CAP INFORMATION- CAP OPTION A

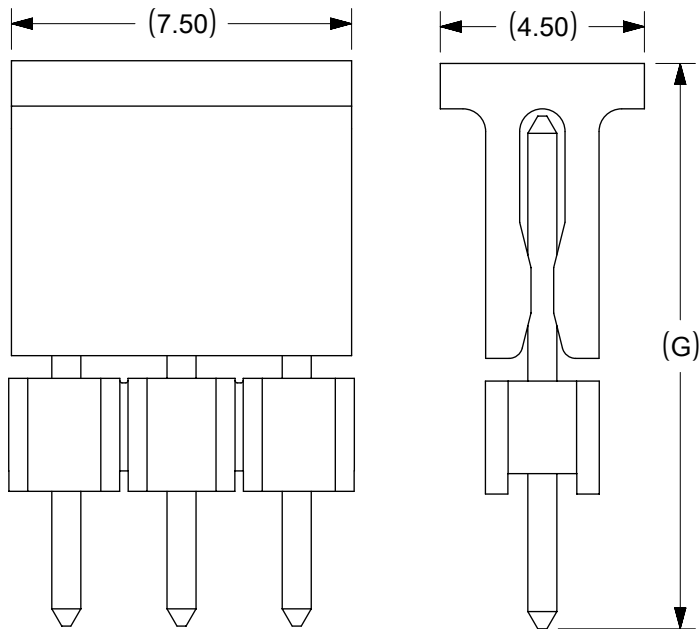


FOR ILLUSTRATION OF ODD CKT
(5CKT AS SHOWN)

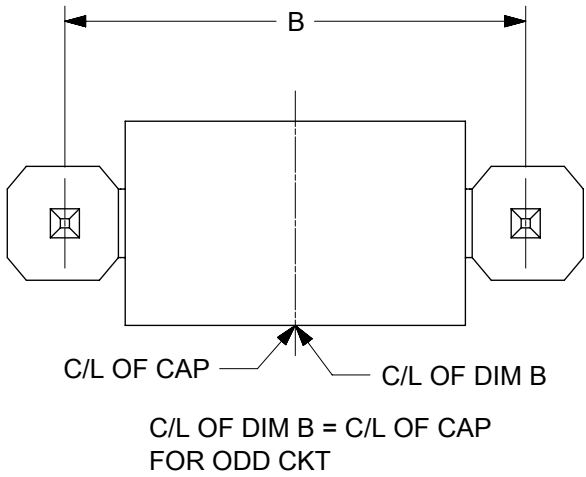


FOR ILLUSTRATION OF EVEN CKT
(4CKT AS SHOWN)

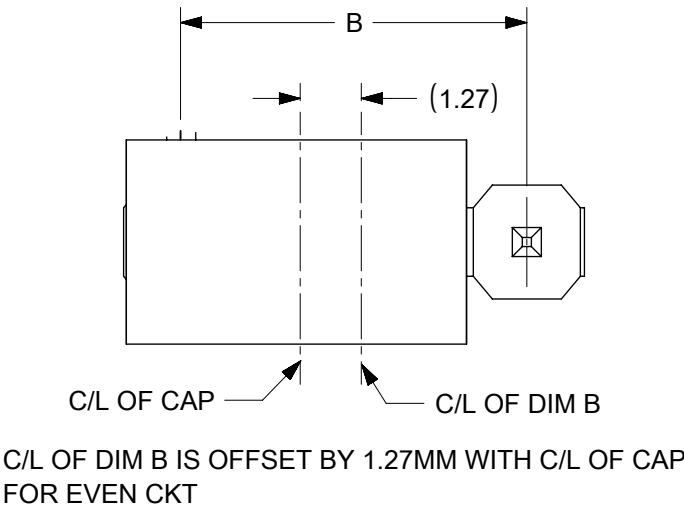


CAP INFORMATION- CAP OPTION B

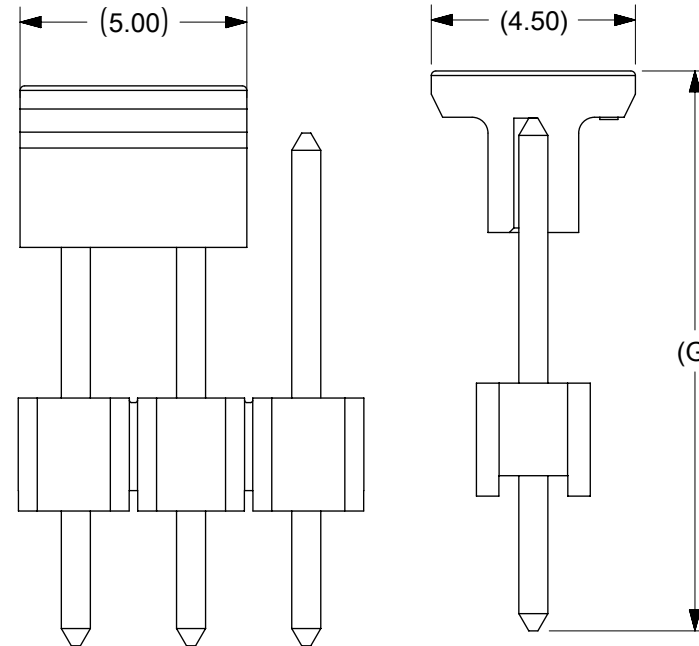

FOR ILLUSTRATION OF ODD CKT
(5CKT AS SHOWN)

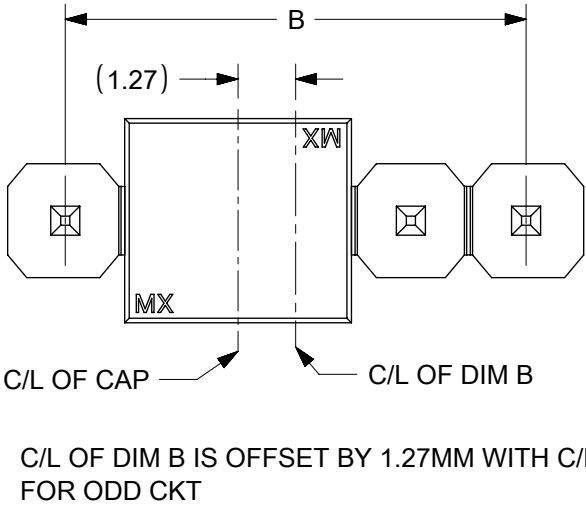

FOR ILLUSTRATION OF EVEN CKT
(4CKT AS SHOWN)

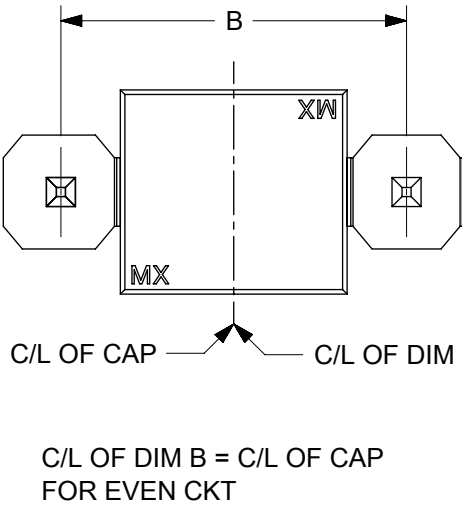

10			9		8		7		6		5		4		3		2		1	
CKT SIZE	DIMENSION			ASSY W/CAP IN T&R	ASSY W/O CAP IN T&R	ASSY W/O CAP IN TUBE	ASSY W/CAP IN TUBE	PART NO. W/O CAP IN TRAY PACKAGING	PART NO. IN BULK PACKAGING	CKT SIZE	VOID PIN	KINK PIN	(G)	DIMENSION			PLATING TYPE	CAP OPTION	REMARKS	
	A	B												OAL	MATING END	SOLDIER TAIL				
	01	2.54																		---
	02	5.08																		2.54
03	7.62	5.08												(F)	M	P				
04	10.16	7.62																		
05	12.70	10.16	-	-	-	-	87891-0108	-	01	-	-	-	10.80	5.08	3.23	5	-	-		
06	15.24	12.70	-	-	-	-	87891-1017	-	01	-	-	-	12.29	6.80	3.00	3	-	-		
07	17.78	15.24	-	-	-	-	87891-0200	-	02	-	-	-	11.76	6.09	3.18	5	-	-		
08	20.32	17.78	-	-	-	-	87891-0205	-	02	-	-	-	11.30	5.84	2.97	4	-	-		
09	22.86	20.32	-	-	-	-	87891-0206	-	02	-	-	-	11.30	5.84	2.97	5	-	-		
10	25.40	22.86	-	-	-	-	87891-0211	-	02	-	-	-	11.30	5.84	2.97	5	-	-		
11	27.94	25.40	-	-	-	-	87891-0207	-	02	-	-	-	9.80	4.00	3.31	5	-	-		
12	30.48	27.94	-	-	-	-	87891-0208	-	02	-	-	-	7.49	4.00	1.00	2	-	-		
13	33.02	30.48	-	-	-	-	87891-0209	-	02	-	-	-	10.80	5.08	3.23	5	-	-		
14	35.56	33.02	-	-	-	-	87891-0210	-	02	-	-	-	31.00	25.54	2.97	5	-	-		
15	38.10	35.56	-	-	-	-	87891-0216	-	02	-	-	-	7.29	2.40	2.40	5	-	-		
16	40.64	38.10	-	-	-	-	87891-0212	-	02	-	-	-	18.37	12.68	3.20	5	-	-		
17	43.18	40.64	-	-	-	-	87891-0211	-	02	-	-	-	26.49	20.80	3.20	5	-	-		
18	45.72	43.18	-	-	-	-	87891-0214	-	02	-	-	-	19.49	13.00	4.00	5	-	-		
19	48.26	45.72	87891-0215	-	-	-	-	-	02	-	-	14.98	13.98	7.49	4.00	5	A	-		
20	50.80	48.26	-	-	-	-	87891-0213	-	02	-	-	-	12.14	5.84	3.81	4	-	-		
21	53.34	50.80	-	-	-	-	87891-0306	-	03	-	-	-	11.30	5.84	2.97	5	-	-		
22	55.88	53.34	-	-	-	-	87891-0308	-	03	-	-	-	11.30	5.84	2.97	5	-	-		
23	58.42	55.88	-	-	-	-	87891-0307	-	03	-	-	-	22.73	18.74	1.50	5	-	-		
24	60.96	58.42	-	-	-	-	87891-0003	-	03	2	-	-	13.72	9.65	1.78	6	-	-		
25	63.50	60.96	-	87891-0312	-	-	-	-	03	-	-	-	11.30	5.84	2.97	4	-	-		
27	68.58	66.04	87891-0311	-	-	-	-	-	03	-	-	12.34	11.30	5.84	2.97	5	B	REFER RPK-87891-0311 (FOR 87891-0311)		
28	71.12	68.58	87891-0313	-	-	-	-	-	03	-	-	12.34	11.30	5.84	2.97	5	B	-		
29	73.66	71.12	-	-	-	-	-	87891-0310	03	-	-	-	6.49	2.00	2.00	5	-	-		
30	76.20	73.66	-	-	-	-	-	-	03	-	-	-	12.14	5.84	3.81	4	-	-		
31	78.74	76.20	-	-	-	-	-	-	04	2	-	-	10.80	5.89	2.41	5	-	-		
32	81.28	78.74	-	-	-	-	-	-	04	-	-	-	35.10	29.71	3.10	6	-	-		
33	83.82	81.28	-	-	-	-	-	-	04	-	-	-	10.09	4.00	3.60	5	-	-		
34	86.36	83.82	-	-	-	-	-	-	04	-	-	-	9.80	4.00	3.31	5	-	-		
35	88.90	86.36	-	-	-	-	-	-	04	-	-	-	31.00	25.54	2.97	5	-	-		
36	91.44	88.90	-	-	-	-	-	-	04	-	-	-	12.14	6.75	2.90	5	-	REFER 878910418-RPK (FOR 87891-0418)		
37	93.98	91.44	-	-	-	-	-	-	04	-	-	-	12.14	6.75	2.90	4	-	-		
38	96.52	93.98	-	-	-	-	-	-	04	-	-	-	15.11	9.01	3.61	5	A	-		
39	99.06	96.52	-	-	-	-	-	-	04	-	-	-	18.03	13.54	2.00	5	-	-		
40	101.60	99.06	-	-	-	87891-0430	-	-	04	-	-	-	13.09	8.00	2.80	5	A	-		

[illegible]

[illegible]