

Quick Die  
Exchange

No Tools  
Required

Adjustable  
Tension

6 Settings

Rubberized  
Grips

Easy to Use


## Quick Interchange Crimp Tools with Slide-Out Dies

Precisely milled, hardened steel dies

Built-in ratchet applies correct pressure to  
ensure a complete crimp



Rubberized comfort grips

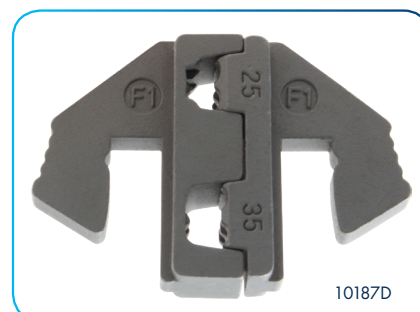

## Exchange Dies with Ease—No Tools Required

These high-precision wire ferrule crimpers feature a built-in ratchet that applies correct pressure to ensure a complete crimp every time and the safety release function allows you to stop a faulty crimp before the crimping cycle is complete. The precisely milled, hardened steel dies have individual square crimping slots for each wire.

- Built-in ratchet applies correct pressure to ensure a complete crimp
- Durable steel construction and hardened dies ensure tool longevity
- Rubberized grips
- Replaceable dies sold separately

### CRIMPING TOOLS

| SKU   | ITEM NAME                                                                                 | JAW TYPE | DIN                               | AWG               | WEIGHT  | PRICE   |
|-------|-------------------------------------------------------------------------------------------|----------|-----------------------------------|-------------------|---------|---------|
| 10178 | Crimp Tool for Wire Ferrules, Insulated Cord End 12 to 22 AWG                             | D        | 0.5, 0.75, 1.0, 1.5, 2.5, 4.0 MM2 | 22/20/18/16/14/12 | 1.2lbs  | \$30.83 |
| 10179 | Crimp Tool for Wire Ferrules, Insulated Cord End Terminals 6 to 10 AWG                    | F        | 6/10/16 MM2                       | 10/8/6            | 0.75lbs | \$49.37 |
| 10187 | Crimp Tool For Insulated Wire Ferrules, Insulated Cord End Terminals                      | F1       | 25/35 MM2                         | N/A               | 1.2lbs  | \$51.66 |
| 10188 | Crimping Tool for Wire Ferrule, Insulated Cord End Terminals AWG 22-18/6-14/12-10         | A        | 0.5-1.0/1.5-2.5/4-6 MM2           | 22-18/6-14/12-10  | 1.2lbs  | \$51.60 |
| 10189 | Crimping Tool for Miniature Wire Ferrules, Insulated Cord Terminals AWG 26-22/24-18/22-16 | A3       | 0.1-0.5/0.25-1.0/0.5-1.5 MM2      | 26-22/24-18/22-16 | 1.2lbs  | \$51.60 |
| 10195 | Crimping Tool Frame                                                                       | N/A      | N/A                               | N/A               | 1.2lbs  | \$30.83 |

### REPLACEABLE DIES

| SKU     | ITEM NAME                 | JAW TYPE | DIN                               | AWG               | WEIGHT  | PRICE   |
|---------|---------------------------|----------|-----------------------------------|-------------------|---------|---------|
| 10189D  | Crimping Die A3           | A3       | N/A                               | 26-22/24-18/22-16 | 0.2lbs  | \$20.83 |
| 10188D  | Crimping Die A            | A        | N/A                               | 22-18/6-14/12-10  | 0.2lbs  | \$20.83 |
| 10187D  | Crimping Die F1           | F1       | 25/35 MM2                         | N/A               | 0.2lbs  | \$20.83 |
| 10178D* | Replacement Crimping Die* | D        | 0.5, 0.75, 1.0, 1.5, 2.5, 4.0 MM2 | 22 to 12 AWG      | 0.15lbs | \$14.17 |
| 10179D* | Replacement Crimping Die* | D        | 6/10/16 MM2                       | 10/8/6            | 0.15lbs | \$14.17 |

\*only compatible with 10178 and 10179 tools with light blue handles