 


1. SPECIFICATION

AC-1201E-RP


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	1.5	
02	Operating Voltage	V	1 ~ 3	
03	Consumption Current	mA (Max)	Mean : 70	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
			Peak : 210	
04	Direct Current Resistance	Ω	6.5 ± 1	
05	Sound pressure level (Distance at 10cm)	dBA (Min)	88	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
06	Rated Frequency	Hz	2730	

REV NO.

REVISION NOTE

APPROVAL

DATE

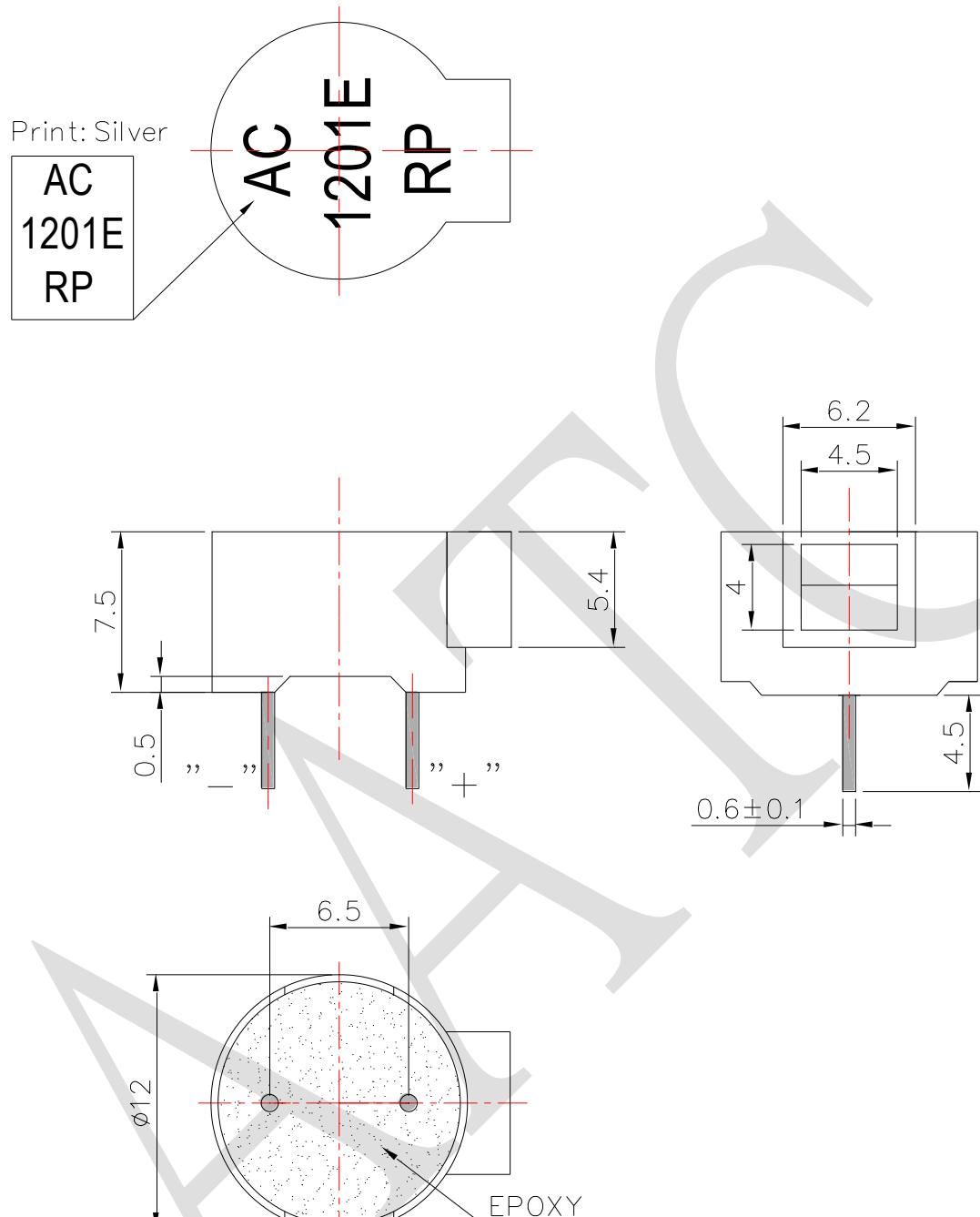

RoHS

TITLE: ELECTRO MAGNETIC BUZZER

DRAWN: Zadk

2012/08/15

SCALE: 4:1 SHEET: 1 of 1

PART NO. AC-1201E-RP

DESIGNED: R&D OF AAT

UNITS: mm

DWG NO. HS-110601

CHECKED:

TOLERANCE ± 0.5 2
REV

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

MATERIAL: NORYL

ONE PLACE DECIMAL $\pm ***$ TWO PLACE DECIMAL $\pm ***$ THREE PLACE DECIMAL $\pm ***$ 

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

