


Connector Location A



Connector Location B

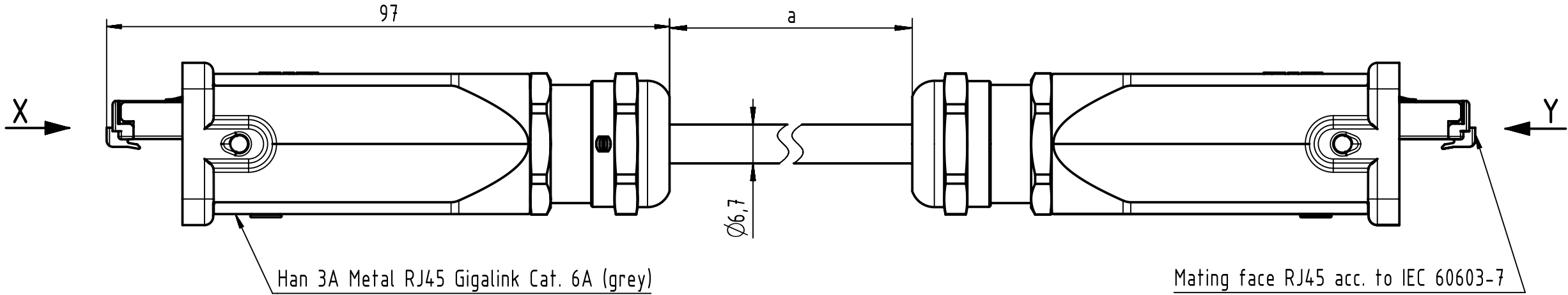

X
male

Loading-Plan
acc. to TIA/EIA 568B

Y
male

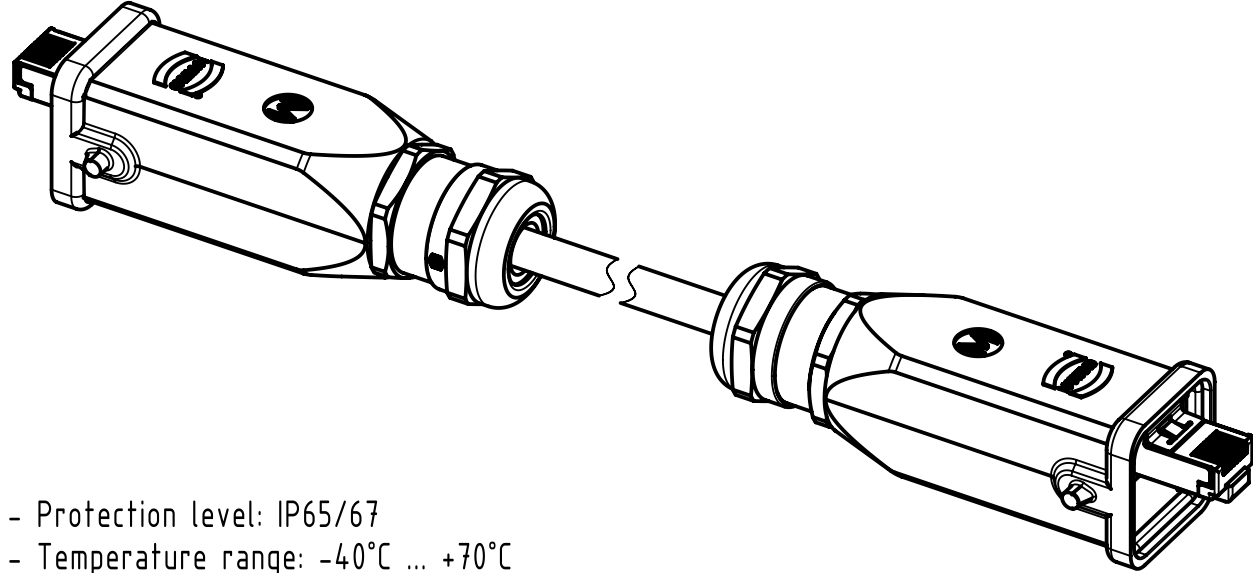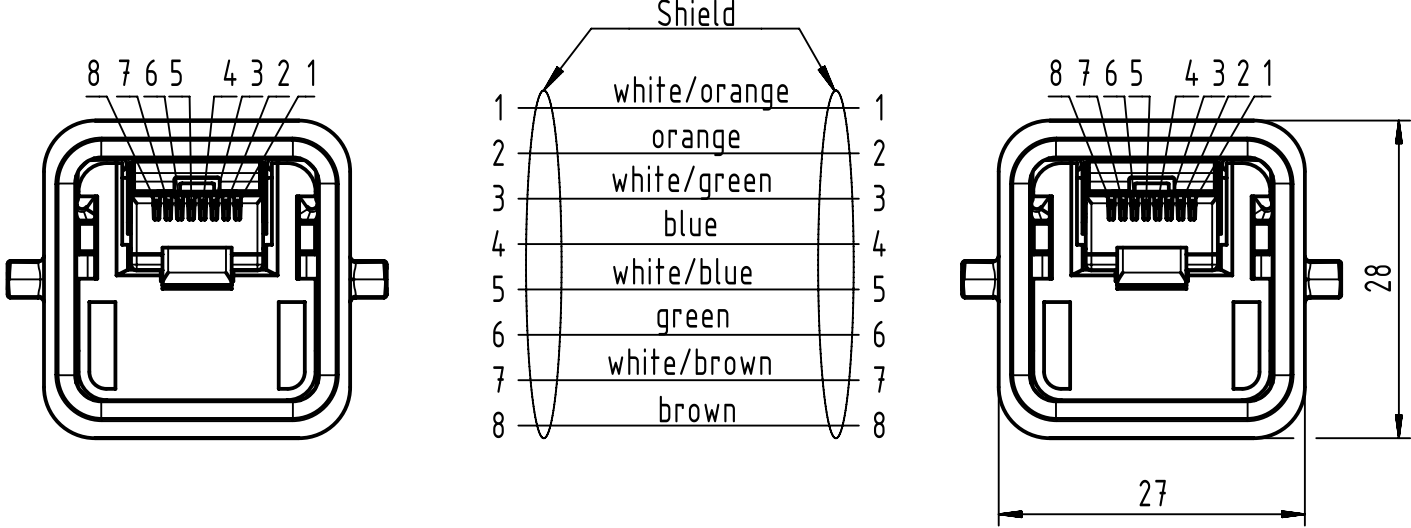

- Protection level: IP65/67
- Temperature range: -40°C ... +70°C

14	09457151116	RJ45 Ethernet stranded cable 4x2xAWG 26/7, outdoor, PVC, Cat. 5, black	20
13	09457151115		15
12	09457151114		10
11	09457151113		9
10	09457151112		8
9	09457151111		7
8	09457151110		6
7	09457151109		5
6	09457151108		4
5	09457151107		3
4	09457151106		2
3	09457151105		1.5
2	09457151104		1
1	09457151103		0.5
Cont. no.	Part no.	Type of cable	Dim. a[m]

All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
All rights reserved		Created by		Inspected by		Standardisation	
Department HCS - RO		STOCHECIC		COSTEA		AVRAM	
HARTING Customised Solutions		Stochechi		Costea		Avram	
D-32339 Espelkamp		Title		Date		State	
		RJ Industrial Cable Assembly		2018-05-11		Final Release	
		Type		Number		Doc-Key / ECM-Nr.	
		TB		094571511XX		100081308/UGD/010/D	
						500000134555	
						Rev. D	
						Page 1/1	