


Connector Location A

Connector Location B




E500416


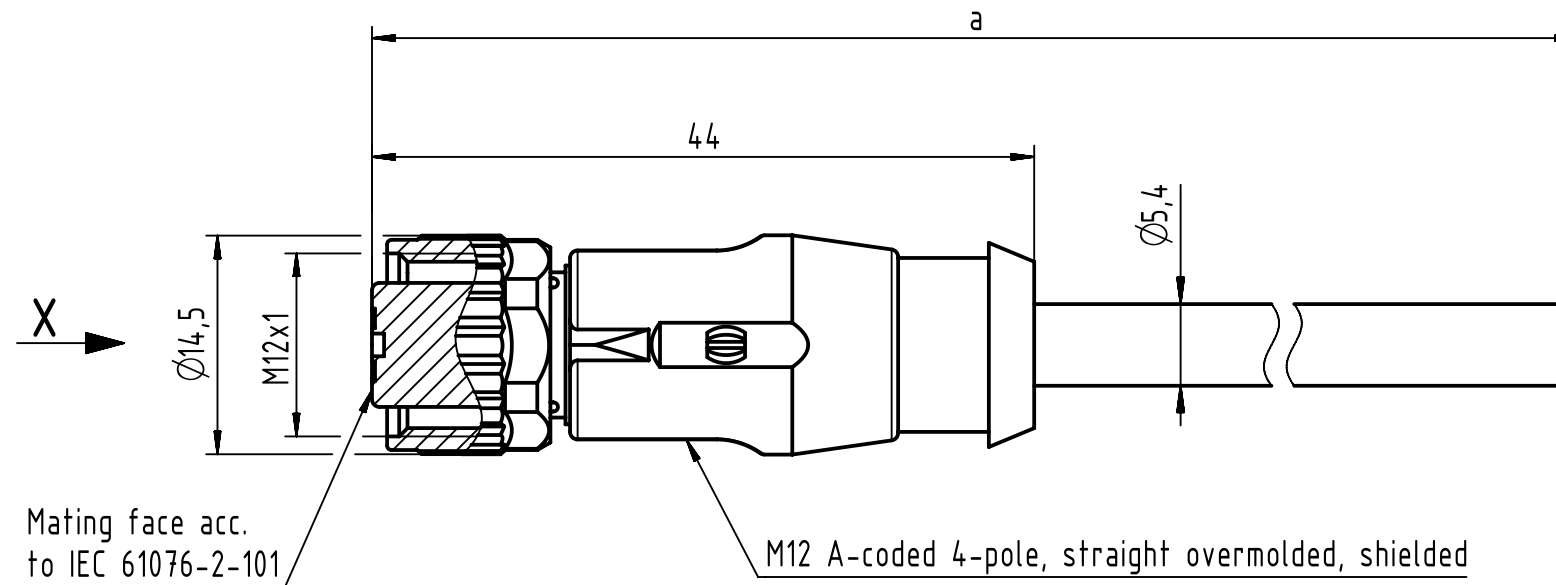


Mating face acc.
to IEC 61076-2-101

M12 A-coded 4-pole, straight overmolded, shielded

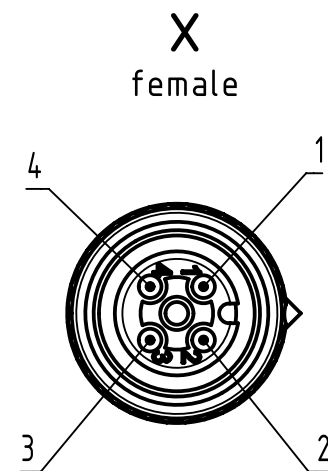

Loading-Plan:

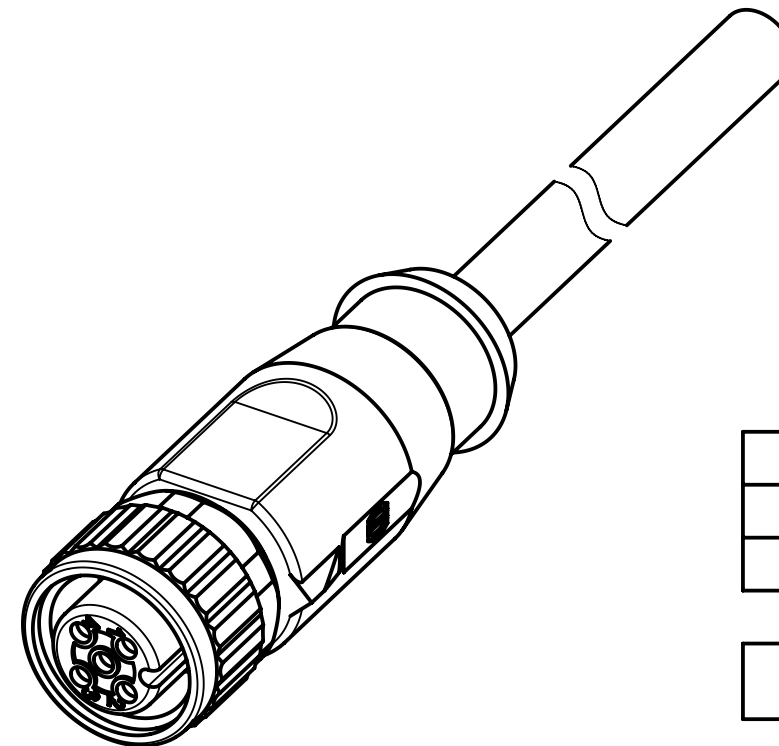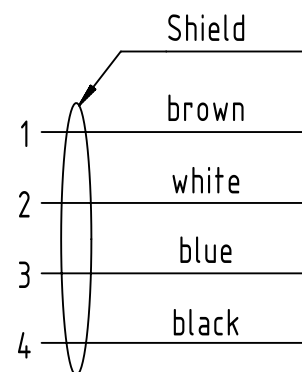

 
4.0 to 100	±1%
0.1 to 3.9	+0.04
a [m]	Tolerance

length in "1m" step	100	XXX=000
	99	XXX=990
	.	.
	.	.
	12	XXX=120
	11	XXX=110
length in "0.1m" step	10	XXX=100
	9.9	XXX=099
	9.8	XXX=098
	.	.
	.	.
	0.4	XXX=004
	0.3	XXX=003
	0.2	XXX=002
	0.1	XXX=001
Step	a [m]	<u>XXX</u>

Part no.	213475004-XXXX
----------	----------------

Type of cable	XX
PVC grey, 4x0.34mm ²	XX=29
PUR black, 4x0.34mm ²	XX=74

- Protection level: IP67
- Temperature range: -25°C ... +80°C

		All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing							
		All rights reserved		Created by COSTEA		Inspected by STOCHECIC Stochechi		Standardisation MUNTEANV Muntean		Date 2019-01-14		State Final Release			
Department		HCS - RO		Title M12 A-coded 4pol st/- f/- shld								Doc-Key / ECM-Nr. 100714865/UGD/013/B 500000144866			
HARTING Customised Solutions				Type TB		Number 213475004XXXXX						Rev. B		Page 1/1	
D-32339 Espelkamp															